

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0673298040

Status:


Active

Overview:

USB Products and Solutions

Description:

Universal Serial Bus (USB) Shielded I/O Receptacle, Type A, Single Upright Right-Angle, 2.00mm Tail Length , 2.10mm Straight Solder Tabs, 1.60mm PCB Thickness, Gold (Au) Flash Plating, Lead-Free

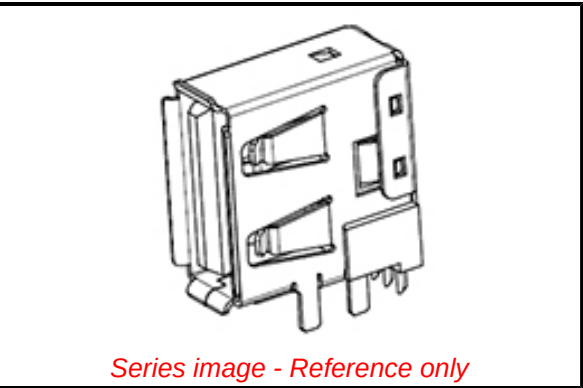

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Packaging Specification PK-67329-804-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	I/O Connectors
Series	67329
Application	Wire-to-Board
Component Type	Receptacle
Overview	USB Products and Solutions
Product Name	USB
Standard	USB 2.0
Type	A
UPC	889056304658
Physical	
Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Durability (mating cycles max)	1500
Gender	Female
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Mounting Style	Upright
Net Weight	1.950/g
Number of Rows	1
Orientation	Right Angle
PC Tail Length	2.00mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	1.40mm
Pitch - Termination Interface	1.40mm
Plating min - Mating	0.051µm
Plating min - Termination	1.270µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Surface Mount Compatible (SMC)	Yes
Termination Interface: Style	Through Hole
Waterproof / Dustproof	No

Electrical

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

67329 Series

Current - Maximum per Contact	1.0A
Grounding to Panel	Yes
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V DC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-67329-804-001
Product Specification	RPS-67329-804-001
Sales Drawing	SD-67329-804-001

This document was generated on 09/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

67329-8040