


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0687840002
Status: Active
Overview: USB Connectors: USB Type-A, USB Type-B, and USB Type-C Plugs and Receptacles
Description: USB Shielded I/O Cable Assembly, USB A-to-Micro-USB B, 1.50m Length, Black, Lead-Free

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-68784-001-001 \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	68784
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Micro-USB Type B
Overview	USB Connectors: USB Type-A, USB Type-B, and USB Type-C Plugs and Receptacles
Product Name	Micro-USB, USB
UPC	883906173746
Physical	
Cable Length	1.50m
Circuits (Loaded)	4, 5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Nickel
Material - Plating Termination	Gold
Material - Resin	PVC
Net Weight	37.700/g
Number of Rows	1
Packaging Type	Bag
Single Ended	No
Waterproof / Dustproof	No
Wire Size AWG	28
Wire/Cable Type	Round
Electrical	
Current - Maximum per Contact	1.8A, 1.0A
Impedance	90Ω
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V AC
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-68784-001-001
Sales Drawing	SD-68784-001-001

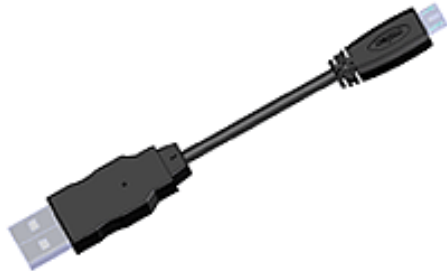

Series image - Reference only

EU ELV Compliant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
Green Image Compliant Not Contained	

Search Parts in this Series
68784 Series

Mates With
Micro-USB B-type Receptacles

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[68784-0002](#)