


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0690201902](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: [Arbor Press Fixture](#)

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family [Application Tooling](#)
Series [207125](#)
Function [Insulation Displacement \(IDT\)](#)
Geographic Area [Global](#)
Level of Automation [Manual](#)
More Detailed Tech Information [applicationtooling@molex.com](#)
Overview [Application Tooling](#)
Product Name [Arbor, Picoflex](#)
Tool Type [Arbor Press](#)
UPC [800753918474](#)
Warranty Disclaimer [CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors \("Molex Tooling"\). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.](#)

Material Info
Reference - Drawing Numbers
[Application Tooling Documents](#) [ATS-690201902-001](#)

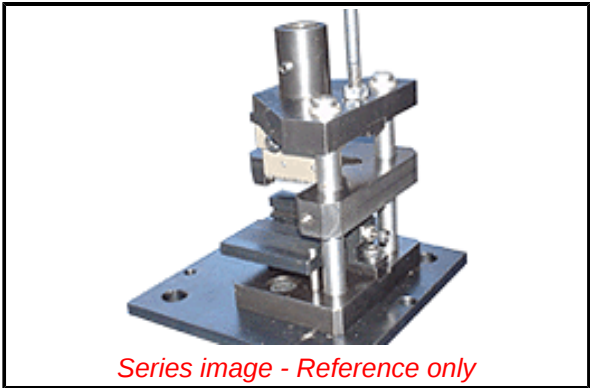

Series image - Reference only

EU ELV
Not Reviewed

EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS Not Reviewed Not Reviewed Not Reviewed
---	---

For more information, please visit [Contact US](#)

Search Parts in this Series	
207125 Series	
Application Tooling Description	FAQ Product #
Picoflex PF-50, Low Profile, IDT Receptacle, 4 Circuits, White, Tin (Sn) Plated, Bag	903270304
Picoflex PF-50, Low Profile, IDT Receptacle, 6 Circuits, White, Tin (Sn) Plated, Bag	903270306
Picoflex PF-50, Low Profile, IDT Receptacle, 8 Circuits, White, Tin (Sn) Plated, Bag	903270308
Picoflex PF-50, Low Profile, IDT Receptacle, 10 Circuits, White, Tin (Sn) Plated, Bag	903270310
Picoflex PF-50, Low Profile, IDT	903270312

Receptacle, 12 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270314</u>
Receptacle, 14 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270316</u>
Receptacle, 16 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270318</u>
Receptacle, 18 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270320</u>
Receptacle, 20 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270322</u>
Receptacle, 22 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270324</u>
Receptacle, 24 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903270326</u>
Receptacle, 26 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273304</u>
Receptacle, 4 Circuits, White, Gold (Au) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273306</u>
Receptacle, 6 Circuits, White, Gold (Au) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273308</u>
Receptacle, 8 Circuits, White, Gold (Au) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273310</u>
Receptacle, 10 Circuits, White, Gold (Au) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273312</u>
Receptacle, 12 Circuits, White, Gold (Au) Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273314</u>

Receptacle, 14	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273316</u>
Low Profile, IDT	
Receptacle, 16	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273318</u>
Low Profile, IDT	
Receptacle, 18	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273320</u>
Low Profile, IDT	
Receptacle, 20	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273322</u>
Low Profile, IDT	
Receptacle, 22	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273324</u>
Low Profile, IDT	
Receptacle, 24	
Circuits, White, Gold	
(Au) Plated, Bag	
Picoflex PF-50,	<u>903273326</u>
Low Profile, IDT	
Receptacle, 26	
Circuits, White, Gold	
(Au) Plated, Bag	
1.27mm Pitch	<u>905841304</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 4	
Circuits	
1.27mm Pitch	<u>905841306</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 6	
Circuits	
1.27mm Pitch	<u>905841308</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 8	
Circuits	
1.27mm Pitch	<u>905841310</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 10	
Circuits	
1.27mm Pitch	<u>905841312</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 12	
Circuits	
1.27mm Pitch	<u>905841314</u>
Picoflex PF-50 IDT	
Receptacle, Low	
Profile, Board-in, 14	
Circuits	
1.27mm Pitch	<u>905841316</u>
Picoflex PF-50 IDT	

Receptacle, Low Profile, Board-in, 16 Circuits	
1.27mm Pitch	<u>905841318</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 18 Circuits	
1.27mm Pitch	<u>905841320</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 20 Circuits	
1.27mm Pitch	<u>905841322</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 22 Circuits	
1.27mm Pitch	<u>905841324</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 24 Circuits	
1.27mm Pitch	<u>905841326</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 26 Circuits	

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[69020-1902](#)