

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0690201908

Status:

Active

Overview:

Application Tooling

Description:

Arbor Press Fixture

Documents:

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207125

Insulation Displacement (IDT)

Global

Manual

applicationtooling@molex.com

Application Tooling

Arbor

Arbor Press

822350736152


CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

M-69020-1908-001

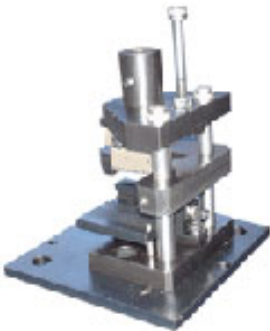

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207125 Series

Application Tooling Description	FAQ Product #
Picoflex PF-50, Low Profile, IDT Receptacle, 4 Circuits, White, Tin (Sn) Plated, Bag	903270304
Picoflex PF-50, Low Profile, IDT Receptacle, 6 Circuits, White, Tin (Sn) Plated, Bag	903270306
Picoflex PF-50, Low Profile, IDT Receptacle, 8 Circuits, White, Tin (Sn) Plated, Bag	903270308
Picoflex PF-50, Low Profile, IDT Receptacle, 10 Circuits, White, Tin (Sn) Plated, Bag	903270310
Picoflex PF-50, Low Profile, IDT	903270312

	Receptacle, 12 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270314</u> Low Profile, IDT
	Receptacle, 14 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270316</u> Low Profile, IDT
	Receptacle, 16 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270318</u> Low Profile, IDT
	Receptacle, 18 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270320</u> Low Profile, IDT
	Receptacle, 20 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270322</u> Low Profile, IDT
	Receptacle, 22 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270324</u> Low Profile, IDT
	Receptacle, 24 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903270326</u> Low Profile, IDT
	Receptacle, 26 Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, <u>903273304</u> Low Profile, IDT
	Receptacle, 4 Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, <u>903273306</u> Low Profile, IDT
	Receptacle, 6 Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, <u>903273308</u> Low Profile, IDT
	Receptacle, 8 Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, <u>903273310</u> Low Profile, IDT
	Receptacle, 10 Circuits, White, Palladium Nickel

with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 12 Circuits, White, Palladium Nickel	<u>903273312</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 14 Circuits, White, Palladium Nickel	<u>903273314</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 16 Circuits, White, Palladium Nickel	<u>903273316</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 18 Circuits, White, Palladium Nickel	<u>903273318</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 20 Circuits, White, Palladium Nickel	<u>903273320</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 22 Circuits, White, Palladium Nickel	<u>903273322</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 24 Circuits, White, Palladium Nickel	<u>903273324</u>
with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 26 Circuits, White, Palladium Nickel	<u>903273326</u>
with Gold (Au) Flash Plated, Bag 1.27mm Pitch Picoflex PF-50 IDT Receptacle, Low Profile, Board-in, 4 Circuits	<u>905841304</u>
1.27mm Pitch Picoflex PF-50 IDT	<u>905841306</u>

Receptacle, Low Profile, Board-in, 6 Circuits	
1.27mm Pitch	<u>905841308</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 8 Circuits	
1.27mm Pitch	<u>905841310</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 10 Circuits	
1.27mm Pitch	<u>905841312</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 12 Circuits	
1.27mm Pitch	<u>905841314</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 14 Circuits	
1.27mm Pitch	<u>905841316</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 16 Circuits	
1.27mm Pitch	<u>905841318</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 18 Circuits	
1.27mm Pitch	<u>905841320</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 20 Circuits	
1.27mm Pitch	<u>905841322</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 22 Circuits	
1.27mm Pitch	<u>905841324</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 24 Circuits	
1.27mm Pitch	<u>905841326</u>
Picoflex PF-50 IDT	
Receptacle, Low Profile, Board-in, 26 Circuits	

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[69020-1908](#)