

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0691271001

Status:

Active

Overview:

Application Tooling

Description:

Semi-Automatic Bench Press PB14 for 4-26 Circuit

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207125

Insulation Displacement (IDT)

Global

Semi-Automatic

applicationtooling@molex.com

Application Tooling

PB14

Pneumatic Press

800753561946

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical

Net Weight


17000.000/g

Material Info

Reference - Drawing Numbers

Application Tooling Documents

TM-691271001-001

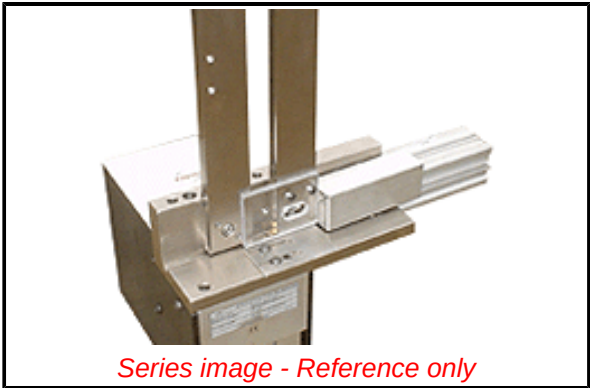

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207125 Series

Use With

691275045 DeTape, 691275043 (110V) DeTape

Application Tooling Description	FAQ Product #
Picoflex PF-50, Low Profile, IDT Receptacle, 4 Circuits, White, Tin (Sn) Plated, Bag	903270304
Picoflex PF-50, Low Profile, IDT Receptacle, 6 Circuits, White, Tin (Sn) Plated, Bag	903270306
Picoflex PF-50, Low Profile, IDT Receptacle, 8 Circuits, White, Tin (Sn) Plated, Bag	903270308
Picoflex PF-50, Low Profile, IDT Receptacle, 10	903270310

	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 12	<u>903270312</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 14	<u>903270314</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 16	<u>903270316</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 18	<u>903270318</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 20	<u>903270320</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 22	<u>903270322</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 24	<u>903270324</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 26	<u>903270326</u>
	Circuits, White, Tin (Sn) Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 4	<u>903273304</u>
	Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 6	<u>903273306</u>
	Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT Receptacle, 8	<u>903273308</u>
	Circuits, White, Palladium Nickel with Gold (Au) Flash Plated, Bag Picoflex PF-50, Low Profile, IDT	<u>903273310</u>

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[69127-1001](#)