

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0713081298](#)
Status: **Active**
Overview: [C-Grid Connector Products](#)
Description: 2.54mm Pitch C-Grid Breakaway Header, Surface Mount, Dual Row, Vertical, 98 Circuits, 0.76µm Gold (Au) Selective Plating, without PCB Locator Pegs, with 8.13mm Mating Pin Length

Documents:

3D Model	Packaging Specification 713080000-PK-000 (PDF)
Drawing (PDF)	Packaging Specification 713080001-PK-000 (PDF)
3D Model (PDF)	Packaging Specification 713080002-PK-000 (PDF)
Product Specification PS-71308-001 (PDF)	Packaging Specification 713080003-PK-000 (PDF)
Application Specification 713080001-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA LR19980

General


Product Family PCB Headers
Series [71308](#)
Application Board-to-Board, Signal, Wire-to-Board
Overview [C-Grid Connector Products](#)
Product Name C-Grid
UPC 822348738724

Physical

Breakaway Yes
Circuits (Loaded) 98
Circuits (maximum) 98
Color - Resin Black
Durability (mating cycles max) 50
Flammability 94V-0
Glow-Wire Capable No
Lock to Mating Part None
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 8.089/g
Number of Rows 2
Orientation Vertical
PCB Locator No
PCB Retention None
Packaging Type Tube
Pitch - Mating Interface 2.54mm
Plating min - Mating 0.813µm
Plating min - Termination 2.032µm
Polarized to Mating Part No
Polarized to PCB No
Shrouded No
Stackable Yes
Temperature Range - Operating -40° to +105°C
Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 3.0A
Voltage - Maximum 250V

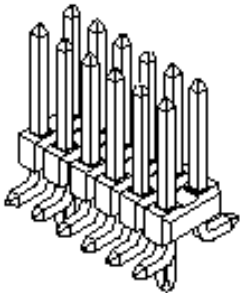

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[71308 Series](#)

Solder Process Data

Lead-freeProcess Capability	REFLOW
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Application Specification	713080001-AS-000
Packaging Specification	713080000-PK-000, 713080001-PK-000, 713080002-PK-000, 713080003-PK-000
Product Specification	PS-71308-001
Sales Drawing	713080000-SD-000

This document was generated on 03/05/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[71308-1298](#)