

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0719790204](#)
Status: **Active**
Overview: [C-Grid Connector Products](#)
Description: 2.54mm Pitch C-Grid Receptacle, Surface Mount, Dual Row, Right-Angle, 8 Circuits


Documents:
[3D Model](#) [Product Specification PS-71973-9999-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	PCB Receptacles
Series	71979
Application	Board-to-Board, Signal
Overview	C-Grid Connector Products
Product Name	C-Grid
UPC	800754701952
Physical	
Circuits (Loaded)	8
Circuits (maximum)	8
Glow-Wire Capable	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.605/g
Number of Rows	2
Orientation	Right Angle
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	2.40mm
Packaging Type	Tube
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Plating min - Mating	0.381µm
Plating min - Termination	1.905µm
Polarized to PCB	No
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical	
Current - Maximum per Contact	1.0A, 2.0A, 3.0A
Voltage - Maximum	500V AC

Material Info

Reference - Drawing Numbers	
Product Specification	PS-71973-9999-001
Sales Drawing	SD-71979-001, SDA-71979-XXXX

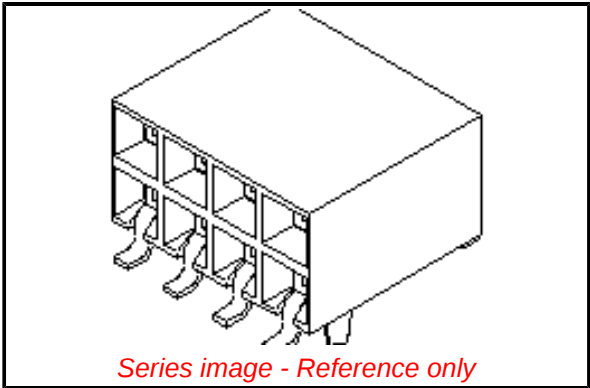

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per -ED/88/2018 (15 January 2019) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[71979 Series](#)

Mates With
[87911 Header](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[71979-0204](#)