

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0731000038
Status: Active
Overview: Type N RF Connectors
Description: 50 Ohms, N Jack, Straight, Bulkhead, RG-142, RG-223, RG-400 and RG-55 Cable

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family RF/Coax Connectors
Series 73276
Overview Type N RF Connectors
Product Name N
Style Cable
Type Medium
UPC 822348386680
Wire/Cable Type RG-142, RG-223, RG-400, RG-55


Physical
Gender Jack
Keying to Mating Part None
Net Weight 42.671/g
Orientation Straight
PCB Mounting N/A
PCB Thickness - Recommended 6.35mm
Packaging Type Bag
Panel Mount Yes
Panel Mount Method Bulkhead
Reverse Polar No

Electrical
Frequency 11 GHz
Impedance 50Ω
Power / Voltage VOLTAGE: 1000 Vrms@Sea Level

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Sales Drawing SD-73100-0038-001, SDA-73100-0038-001

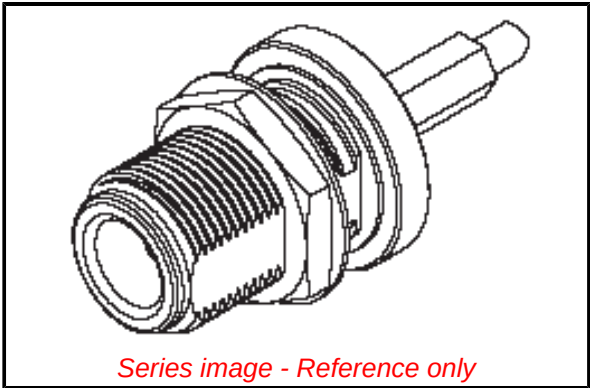

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[73276 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[73100-0038](#)