


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0731160026](#)
Status: **Active**
Overview: [RF Connectors and Microwave Products](#)
Description: MCRF-to-Pigtail, 1.32mm Cable Diameter, Length 230.13mm, H25, 50 Ohms, One Piece Per Bag

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	73116
Assembly Configuration	Single Ended Connector
Connector to Connector	MCRF-to-Pigtail
Overview	RF Connectors and Microwave Products
Product Name	MCRF, RF
Type	RF Cable Assembly
UPC	884982813557
Physical	
Cable Length	230.13mm (9.060")
Circuits (Loaded)	0
Gender	Plug-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Resin	Polyester
Net Weight	0.800/g
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Coaxial
Electrical	
Impedance	50Ω
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73116-002-001

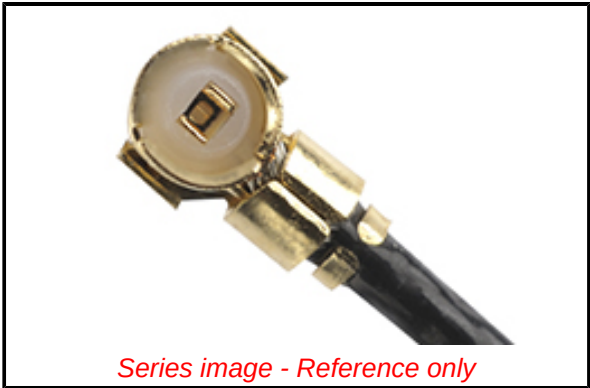

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[73116](#) Series

Mates With
[734120110](#) MCRF, 50 Ohm, Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[73116-0026](#)