


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0731160067](#)
Status: **Active**
Overview: RF Connectors and Microwave Products
Description: MCRF-to-MCRF, 0.81mm Cable Diameter, Length 228.6mm, H18, 50 Ohms, One Piece Per Bag

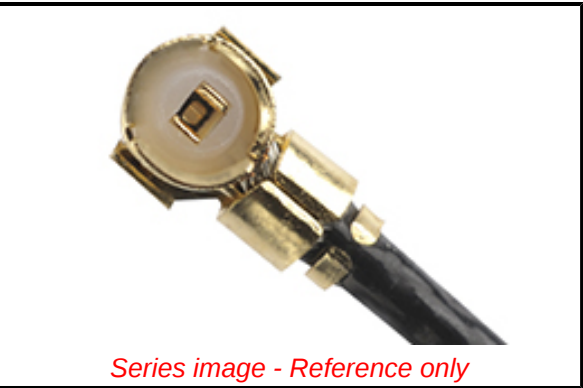

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Cable Assemblies
Series [73116](#)
Assembly Configuration Dual Ended Connectors
Connector to Connector MCRF-to-MCRF
Overview RF Connectors and Microwave Products
Product Name MCRF, RF
Type RF Cable Assembly
UPC 884982868359

Physical
Cable Length 228.60mm
Circuits (Loaded) 0
Gender Plug/Plug
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Resin Polyester
Net Weight 0.470/g
Number of Rows 1
Packaging Type Bag
Single Ended No
Wire/Cable Type Coaxial

Electrical
Impedance 50Ω

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Sales Drawing SD-73116-006-001

EU ELV
Not Relevant

EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained

Search Parts in this Series
[73116](#) Series

Mates With
[734120110](#) MCRF, 50 Ohm, Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[73116-0067](#)