

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:0740578502

Status:Active

Description:VHDM 6 Row BP Assy

Documents:

- Drawing (PDF)

Product Specification PS-74031-999-001 (PDF)
- Packaging Specification PK-74057-003-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

UPC

Backplane Connectors

74057

822350225298

Physical

Flammability

Net Weight

94V-0

10.885/g

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Reference - Drawing Numbers

Packaging Specification


Product Specification

Sales Drawing

PK-74057-003-001

PS-74031-999-001

SD-74057-002-001

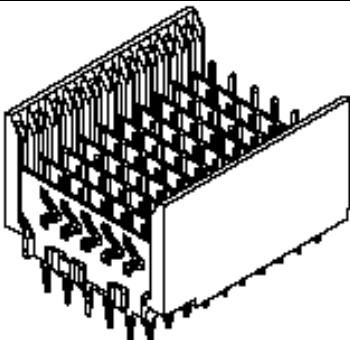

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Dihexyl-phthalate
Phenanthrene
Imidazolidine-2-thione
Dipentyl phthalate
bis(2-(2-
methoxyethoxy)ethyl)
ether
Benzo(ghi)perylene
Octanoic acid,
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-
pen
Dodecamethylcyclohexasiloxane
Octamethylcyclotetrasiloxane
1,2-
Benzenedicarboxylic
acid, bis(3-
methylbutyl)
1,2-diethoxyethane
Dibutyltin-dichloride
C.I. Direct Black 38
Ammonium-
pentadecafluorooctanoate
Phenol, 2-(2H-
benzotriazol-2-yl)-4,6-
bis(1,1-dim
2,4-Di-tert-butyl-6-(5-
chlorobenzotriazol-2-
yl)p
2-(2H-Benzotriazol-2-
yl)-4,6-
ditertpentylphenol
2-(2H-Benzotriazol-2-
yl)-4-(tert-butyl)-6-
(sec-b
Terphenyl,
hydrogenated

diisohexyl phthalate
1,2-Benzenedicarboxylic acid, dipentyl ester, bran-pentyl-isopentylphthalate
Aluminosilicate
Refractory Ceramic Fibres
Nonadecafluorodecanoic acid (PFDA) and its sodium
Perfluorobutane sulfonic acid (PFBS) and its salt
Fluoranthene
Pyrene
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]octa-2,4,6,8,10,12-hexaene
Methylhexahydrophthalic anhydride
Lead chromate
Lead chromate molybdate sulfate red
Lead sulfochromate yellow
Tris(2-chloroethyl) phosphate
Boric acid, disodium salt, hydrate
Strontium-chromate
1,2-Benzenedicarboxylic acid, di-C7-11-branched
Potassium hydroxyoctaoxodizincatedichromate
Pentazinc-chromate-octahydroxide
1,2-Dimethoxyethane
Decabromodiphenylether
Diboron-trioxide
Cadmium-oxide
Cadmium-sulphide
Lead(II,IV)-oxide
pyrochlore, antimony lead yellow
Lead-dinitrate
Lead oxide sulfate (Pb2O(SO4))
Lead-titanium-trioxide
Trilead-dioxide-phosphonate
Tetralead-trioxide-sulphate
Dioxobis(stearato)trilead
Cyanamide, lead(2+) salt (1:1)
Cadmium Hydroxide
Sulfurous Acid, Lead Salt, Dibasic
Silicic acid (H2Si2O5), barium salt (1:1), lead-[Phthalato(2-)]dioxotrilead

Fatty Acids, C16-18,
Lead Salts
N,N-
Dimethylformamide
Halogen-Free
Status
Low-Halogen

For more information, please visit [Contact US](#)

China ROHS
ELV
RoHS Phthalates

Green Image
Not Relevant
Not Contained

Search Parts in this Series

[74057](#) Series

Application Tooling | **FAQ**
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Signal Pin Inserter Repair Tool	622015700
6-Row Pin and Shield Repair Tool	622015800
6-Row Shield Extraction Tool	622016000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

74057-8502