

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0745480218

Status:


Active

Overview:

iPass Connector System

Description:

External iPass Mini Multi-Lane SAS Guide Frame for Standard Host Boards, 1-by-2 Port Size, 0° Cage Angle Port Keying 2

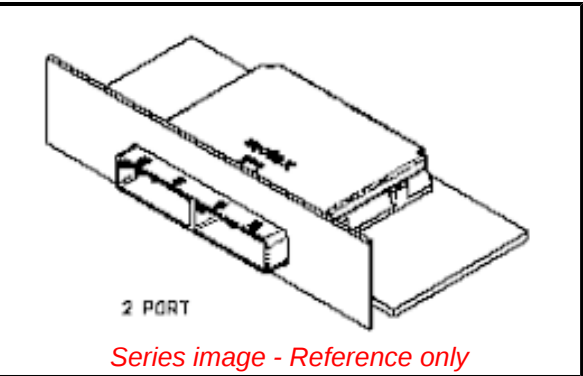

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Packaging Specification PK-74548-027-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	EMI Cages
Series	74548
Application	Module-to-Board
Comments	0 Degree -SAS
Component Type	Guide Frame
Overview	iPass Connector System
Product Name	Mini-SAS
UPC	822350799430
Physical	
EMI Panel / Bezel Mount	Behind the Bezel
Light Pipes per Port	0
Material - Metal	Zinc Die Cast
Net Weight	21.000/g
Orientation	Horizontal
Packaging Type	Tray
Port Configuration	1x2
Rear Legs	0
Termination Interface: Style	N/A
Thermal Height	N/A
Thermal Solutions	Closed Top
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-74548-027-001
Sales Drawing	SD-74548-200-001

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Compliant

Not Contained

Search Parts in this Series

74548 Series

Mates With

74547 iPass Cable Assembly

Use With

75586 Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[74548-0218](#)