

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0756405001

Status:

Active

Overview:

SFP+ and SFP Interconnect Solutions

Description:

Small Form-factor Pluggable (SFP) Stacked 2-by-1 Multi-Port Connector with 4 Lightpipes, with Press-fit PC Tails, 40 Circuits, Lead-Free

Documents:

3D Model	Application Specification AS-75310-001-001 (PDF)
Drawing (PDF)	Application Specification AS-76090-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-75462-001-001 (PDF)
Product Specification PS-75310-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification


CSA	LR19980
UL	E29179

General

Product Family	I/O Connectors
Series	75640
Application	Module-to-Board
Comments	With 4 Lightpipes
Component Type	Receptacle
Overview	SFP+ and SFP Interconnect Solutions
Product Name	SFP
Type	N/A
UPC	822350235419

Physical

Circuits (Loaded)	40
Circuits (maximum)	40
Color - Resin	Black, Clear (Blue Tint)
Durability (mating cycles max)	200
Flammability	94V-0
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic, Polycarbonate
Net Weight	28.326/g
Orientation	Right Angle
PC Tail Length	3.05mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	2.40mm
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.80mm
Pitch - Termination Interface	0.80mm
Plating min - Mating	0.762µm
Plating min - Termination	0.762µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole - Compliant Pin
Waterproof / Dustproof	No

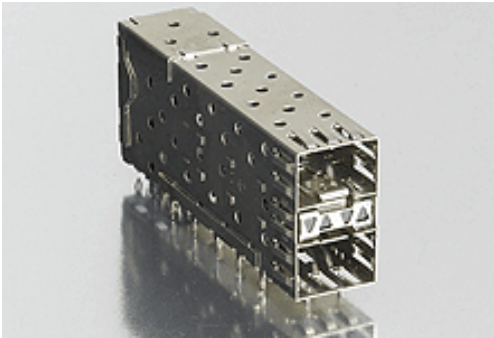

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

75640 Series

Use With

759510999 SFP Dust Plug

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Extraction Tool, 2 x 1622029930
Medium

Electrical

Current - Maximum per Contact	0.5A
Shield Type	EMI Fingers
Shielded	Yes
Voltage - Maximum	30V

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Application Specification	AS-75310-001-001, AS-76090-001-001
Packaging Specification	PK-75462-001-001
Product Specification	PS-75310-001-001
Sales Drawing	SD-75640-001-001, SD-75640-004-001

This document was generated on 01/03/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[75640-5001](#)