

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0760105317](#)
Status: **Active**
Overview: [iPass Connector System](#)
Description: 0.80mm Pitch iPass I/O Connector Shell, Vertical, Through Hole 1.96mm, 68 Circuits, Right Key

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-76010-002 \(PDF\)](#)

General

Product Family I/O Connectors
Series [76010](#)
Application Wire-to-Board
Component Type Shell Body
Overview [iPass Connector System](#)
Product Name iPass
Type N/A
UPC 822350748827

Physical


Boot Color N/A
Circuits (Loaded) N/A
Circuits (maximum) 68
Circuits Detail 68
Durability (mating cycles max) 25
Gender N/A
Keying to Mating Part Yes
Lock to Mating Part None
Material - Metal Copper-Nickel-Zinc
Material - Plating Mating N/A
Net Weight 2.793/g
Number of Rows 0
Orientation Vertical
PC Tail Length 1.96mm
PCB Locator No
PCB Retention Yes
Packaging Type Tray
Panel Mount N/A
Pitch - Mating Interface N/A
Polarized to Mating Part N/A
Polarized to PCB Yes
Surface Mount Compatible (SMC) N/A
Temperature Range - Operating -40° to +80°C
Termination Interface: Style Through Hole
Waterproof / Dustproof No
Wire Size AWG N/A

Electrical

Current - Maximum per Contact N/A
Grounding to Panel None
Shield Type Full Shield
Shielded Yes
Voltage - Maximum N/A

Solder Process Data

Duration at Max. Process Temperature (seconds) 015

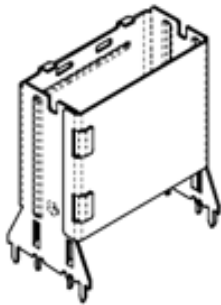

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free
Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[76010](#) Series

Mates With

[79575](#) iPass Internal Cable, [74563](#) iPass Mini-SAS Internal Cable, [79576](#) iPass 36 Circuit-SATA Fanout Cable, [74573](#) iPass 36 Circuit RA-SATA Cable, [79536](#) iPass 36 Circuit SATA Cable, [74562](#) iPass 36 Circuit Right Angle

Use With

[75577](#) 0.80mm Pitch iPass I/O Connector

Lead-free	Process Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature		001
Process Temperature max. C		260
Material Info		
Reference - Drawing Numbers		
Packaging Specification		PK-76010-002
Sales Drawing		SD-76010-002

This document was generated on 04/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

76010-5317