

PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION

**Part Number:** [0760105327](#)  
**Status:** **Active**  
**Overview:** [iPass Connector System](#)  
**Description:** 0.80mm Pitch iPass I/O Connector Shell, Vertical, Through Hole 1.96mm, 68 Circuits, Dual Key

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Packaging Specification PK-76010-002 \(PDF\)](#)

**General**

Product Family I/O Connectors  
Series [76010](#)  
Application Wire-to-Board  
Component Type Shell Body  
Overview [iPass Connector System](#)  
Product Name iPass  
Type N/A  
UPC 822350748834

**Physical**


Boot Color N/A  
Circuits (Loaded) N/A  
Circuits (maximum) 68  
Circuits Detail 68  
Durability (mating cycles max) 25  
Gender N/A  
Keying to Mating Part Yes  
Lock to Mating Part None  
Material - Metal Copper-Nickel-Zinc  
Material - Plating Mating N/A  
Net Weight 2.798/g  
Number of Rows 0  
Orientation Vertical  
PC Tail Length 1.96mm  
PCB Locator No  
PCB Retention Yes  
Packaging Type Tray  
Panel Mount N/A  
Pitch - Mating Interface N/A  
Polarized to Mating Part N/A  
Polarized to PCB Yes  
Surface Mount Compatible (SMC) N/A  
Temperature Range - Operating -40° to +80°C  
Termination Interface: Style Through Hole  
Waterproof / Dustproof No  
Wire Size AWG N/A

**Electrical**

Current - Maximum per Contact N/A  
Grounding to Panel None  
Shield Type Full Shield  
Shielded Yes  
Voltage - Maximum N/A

**Solder Process Data**

Duration at Max. Process Temperature (seconds) 015

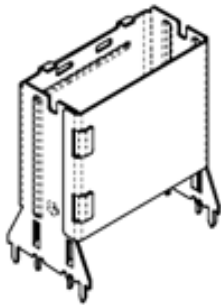

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[76010](#) Series

**Mates With**

[79575](#) iPass Internal Cable, [74563](#) iPass Mini-SAS Internal Cable, [79576](#) iPass 36 Circuit-SATA Fanout Cable, [74573](#) iPass 36 Circuit RA-SATA Cable, [79536](#) iPass 36 Circuit SATA Cable, [74562](#) iPass 36 Circuit Right Angle

**Use With**

[75577](#) 0.80mm Pitch iPass I/O Connector

|                                         |                    |              |
|-----------------------------------------|--------------------|--------------|
| Lead-free                               | Process Capability | SMC&WAVE     |
| Max. Cycles at Max. Process Temperature |                    | 001          |
| Process Temperature max. C              |                    | 260          |
| <b>Material Info</b>                    |                    |              |
| <b>Reference - Drawing Numbers</b>      |                    |              |
| Packaging Specification                 |                    | PK-76010-002 |
| Sales Drawing                           |                    | SD-76010-002 |

This document was generated on 04/05/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[76010-5327](#)