


PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION

**Part Number:** [0765001117](#)  
**Status:** **Active**  
**Overview:** [Impact Backplane Connector and Cable Assembly System](#)  
**Description:** Impact 100 Ohm 4 Pair RAM Right-Angle Header, Unguided, Left Endwall, 10 Columns, 120 Circuits, Pin Length 4.90mm, Plated Through Hole Dimension 0.39mm, Lead-Free

|                                                                  |                                                                   |
|------------------------------------------------------------------|-------------------------------------------------------------------|
| <b>Documents:</b>                                                |                                                                   |
| <a href="#">3D Model</a>                                         | <a href="#">Application Specification AS-76060-994-001 (PDF)</a>  |
| <a href="#">3D Model (PDF)</a>                                   | <a href="#">Application Specification AS-76060-9999-001 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>                                    | <a href="#">Packaging Specification PK-70873-041-001 (PDF)</a>    |
| <a href="#">Product Specification PS-76060-999-001 (PDF)</a>     | <a href="#">Symbol Footprint Data SYM-76500-1117-001 (PDF)</a>    |
| <a href="#">Application Specification AS-76060-990-001 (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a>              |

|                                |                                                                      |
|--------------------------------|----------------------------------------------------------------------|
| <b>Agency Certification</b>    |                                                                      |
| UL                             | E29179                                                               |
| <b>General</b>                 |                                                                      |
| Product Family                 | Backplane Connectors                                                 |
| Series                         | <a href="#">76500</a>                                                |
| Application                    | Coplanar                                                             |
| Application Tooling Documents  | TM-622018799-001                                                     |
| Component Type                 | PCB Header                                                           |
| Overview                       | <a href="#">Impact Backplane Connector and Cable Assembly System</a> |
| Product Name                   | Impact                                                               |
| UPC                            | 884982622494                                                         |
| <b>Physical</b>                |                                                                      |
| Circuits (Loaded)              | 120                                                                  |
| Circuits (maximum)             | 120                                                                  |
| Color - Resin                  | Black                                                                |
| Durability (mating cycles max) | 200                                                                  |
| First Mate / Last Break        | No                                                                   |
| Flammability                   | 94V-0                                                                |
| Guide to Mating Part           | No                                                                   |
| Keying to Mating Part          | None                                                                 |
| Material - Metal               | High Performance Alloy (HPA)                                         |
| Material - Plating Mating      | Gold                                                                 |
| Material - Plating Termination | Tin                                                                  |
| Material - Resin               | High Temperature Thermoplastic                                       |
| Net Weight                     | 11.750/g                                                             |
| Number of Columns              | 10                                                                   |
| Number of Pairs                | 4                                                                    |
| Number of Rows                 | 12                                                                   |
| Orientation                    | Right Angle                                                          |
| PC Tail Length                 | 1.20mm                                                               |
| PCB Locator                    | No                                                                   |
| PCB Retention                  | Yes                                                                  |
| PCB Thickness - Recommended    | 1.00mm                                                               |
| Packaging Type                 | Tray                                                                 |
| Pitch - Mating Interface       | 1.90mm                                                               |
| Pitch - Termination Interface  | 1.90mm                                                               |
| Plating min - Mating           | 0.762µm                                                              |
| Polarized to PCB               | No                                                                   |
| Stackable                      | No                                                                   |
| Temperature Range - Operating  | -55° to +85°C                                                        |

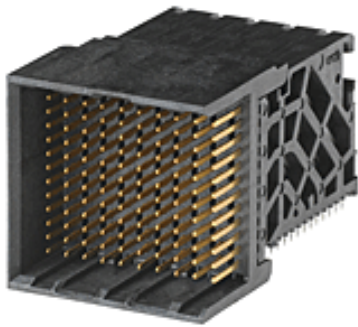

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

**China RoHS**

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[76500](#) Series

**Mates With**

[76160](#) Impact 100 Ohm Daughtercard

|                                    |                                                          |
|------------------------------------|----------------------------------------------------------|
| Termination Interface: Style       | Through Hole - Compliant Pin                             |
| <b>Electrical</b>                  |                                                          |
| Current - Maximum per Contact      | 0.75A                                                    |
| Data Rate                          | 25.0 Gbps                                                |
| Impedance                          | 100Ω                                                     |
| Shield Type                        | N/A                                                      |
| Shielded                           | No                                                       |
| Voltage - Maximum                  | 30V AC (RMS)/DC                                          |
| <b>Material Info</b>               |                                                          |
| <b>Reference - Drawing Numbers</b> |                                                          |
| Application Specification          | AS-76060-990-001, AS-76060-994-001,<br>AS-76060-9999-001 |
| Electrical Model Document          | EE-76500-002-002                                         |
| Packaging Specification            | PK-70873-041-001                                         |
| Product Specification              | PS-76060-999-001                                         |
| S-Parameter Model                  | SP-76500-002-002                                         |
| Sales Drawing                      | SD-76500-001-001                                         |
| Symbol/Footprint Data              | SYM-76500-1117-001                                       |

This document was generated on 09/21/2021

PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

76500-1117