

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0830009502

Status:


Active

Overview:

Commercial Micro-D High-Density Connectors

Description:

Commercial Micro-D Socket Terminal, 5,000 per Reel

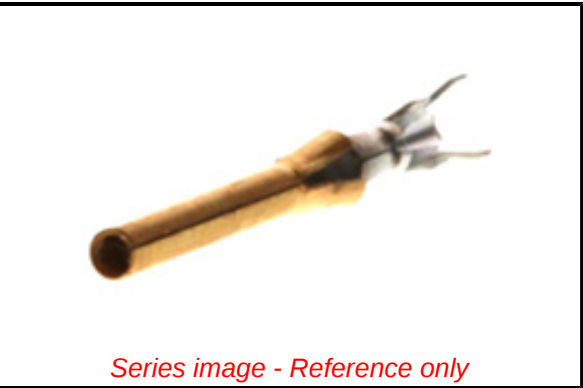

Series image - Reference only

Documents:

Drawing (PDF)

Packaging Specification PK-83000-004-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	83000
Application	Signal, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	Commercial Micro-D High-Density Connectors
Packaging Alternative	830000083 (Loose)
Product Name	Commercial Micro-D
UPC	800753013766

Physical	
Gender	Female
Material - Metal	Beryllium Copper
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	280.090/mg
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.75mm max.
Wire Size AWG	26, 28
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-83000-004-001
Sales Drawing	SD-83000-002-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Dodecamethylcyclohexasiloxane
Octamethylcyclotetrasiloxane
methoxyacetic acid
1,2-diethoxyethane
2-methylimidazole
1-vinylimidazole
1,3-Propanesultone
henicosafuoroundecanoic
acid
sodium
peroxometaborate
1,7,7-trimethyl-3-
(phenylmethylene)bicyclo[2.2.1
1,2-
Benzenedicarboxylic
acid, dihexyl ester,
bra
diisohexyl phthalate
pentacosafuorotridecanoic
acid
2-Methyl-1-(4-
methylthiophenyl)-2-
morpholinoprop
4,4-
isobutylethylidenediphenol
2-benzyl-2-
dimethylamino-4-
morpholinobutyropheno
3-ethyl-2-methyl-2-
(3-methylbutyl)-1,3-
oxazolidi
Hydrazine
Disodium tetraborate
Boric acid
Trixylyl phosphate

2,3,3,3-tetrafluoro-2-(heptafluoropropoxy)propio
Tris(4-nonylphenyl, branched and linear)
phosphi
Fluoranthene
Pyrene
Diocetyl tin dilaurate, stannane, dioctyl-, bis(co
Perfluorononan-1-oic acid
(2,2,3,3,4,4,5,5,6,6,7
4-(1,1,3,3-tetramethylbutyl)phenol, ethoxylated
Methylhexahydrophthalic anhydride
Sodium perborate; perboric acid, sodium salt
5-sec-butyl-2-(2,4-dimethylcyclohex-3-en-1-yl)-5
Perfluorohexane-1-sulphonic acid and its salts
heptacosafuorotetradecanoic acid
Arsenic acid
(H₃AsO₄), triethyl ester
Dibutylphthalate
Di-(2-ethylhexyl)phthalat
Butylbenzylphthalate
2,4-Dinitrotoluene
Diisobutyl-phthalate
Boric acid, disodium salt, hydrate
Trichloroethylene
1-Methyl-2-pyrrolidone
formamide
4,4'-bis(dimethylamino)benzophenone
N,N,N',N'-tetramethyl-4,4'-methylenedianiline
1,2-bis(2-methoxyethoxy)ethane
4,4'-bis(dimethylamino)-4''-(methylamino)trityl
Diboron-trioxide
 $\alpha,\alpha^{\#}$ Bis[4-(dimethylamino)phenyl]-4(phenylamino)
Cadmium-chloride
Silicic acid (H₂Si₂O₅), barium salt (1:1), lead-
diethyl sulphate
propylene oxide
Acetamide, N-methyl-

Phenanthrene
Dinoseb
butyl 4-
hydroxybenzoate
4-tert-butylphenol
nitrobenzene
Ethylenediamine
furan
2-Methoxyethyl
acetate
C,C'-
azodi(formamide)
bis(2-(2-
methoxyethoxy)ethyl)
ether
tricosafuorododecanoic
acid
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[83000 Series](#)

Use With
[83611](#) , [83619](#) , [83612](#) , [83614](#)

Application Tooling | **FAQ**
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Description	Product #
PremiumGrade	638114800
Hand Crimp Tool for 1.27mm Commercial Micro D Terminals, 26-28 AWG	
T2 Terminator Die	638522000
FineAdjust Applicator	638622000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[83000-9502](#) [83000-9502 \(Cut Strip\)](#) [83000-9502 \(Mouser Reel\)](#)