

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0850843612

Status:


Active

Overview:

SRC - Sealed Rectangular Connectors

Description:

SRC Housing, Female, Hybrid 48 Pin Mixed Power and Signal (36 x MX150 + 12 x MX150L), SPS/Nylon, Black

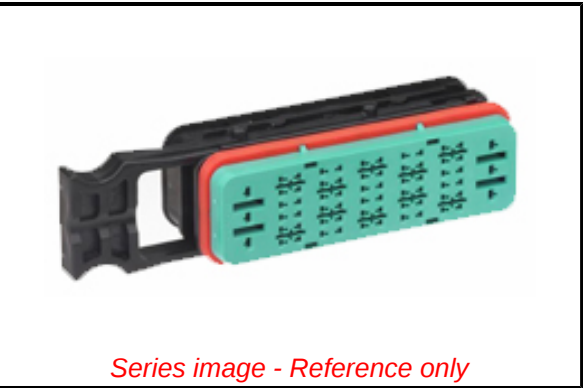

Documents:

Drawing (PDF)

Product Specification 850700010-K (PDF)

Product Specification 937320001-P (PDF)

Packaging Specification 937320001-K (PDF)

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

General	
Product Family	Crimp Housings
Series	85084
Application	Power, Signal, Wire-to-Wire
Overview	SRC - Sealed Rectangular Connectors
Product Literature Order No	987650-7391
Product Name	SRC
UPC	887191068138
Physical	
Circuits (maximum)	48
Circuits Detail	36 x MX150™ + 12 x MX150L™
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	SPS/Nylon
Net Weight	108.180/g
Number of Rows	10
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	937320001-K
Product Specification	850700010-K, 937320001-P
Sales Drawing	850840700-000

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Contained Per -

ED/30/2017 (7 July

2017)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

85084 Series

Mates With

SRC Power Blade Housing 937923612

Use With

MX150 Female Terminals 33012 . MX150L

Female Terminal 19434

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[85084-3612](#)