

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0872633225
Status: Active
Overview: Milli-Grid Connector System
Description: 2.00mm Pitch Milli-Grid Receptacle, Surface Mount, Bottom Entry, 0.76µm Gold (Au) Selective, 32 Circuits, without Pick-and-Place Cap, Tube, Lead-Free

Documents:

3D Model	Packaging Specification PK-87263-0001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-87263-300-001 (PDF)
Product Specification PS-87263-001 (PDF)	Brochure (PDF)
Application Specification 503940001-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Receptacles
Series	87263
Application	Board-to-Board, Signal
Overview	Milli-Grid Connector System
Product Name	Milli-Grid
UPC	822348482214

Physical


Circuits (Loaded)	32
Circuits (maximum)	32
Color - Resin	Black
Durability (mating cycles max)	25
Flammability	94V-0
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	0.611/g
Number of Rows	2
Orientation	Bottom Entry
PCB Locator	Yes
PCB Retention	None
Packaging Type	Tube
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Plating min - Mating	0.762µm
Polarized to Mating Part	No
Polarized to PCB	Yes
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

Solder Process Data

Duration at Max. Process Temperature (seconds)	014
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	265

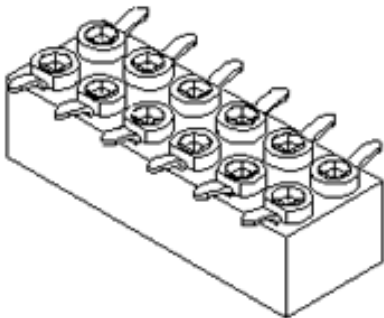

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

87263 Series

Mates With

87759 Vertical, Surface Mount, Stackable
PCB Headers, 87760 Right Angle, Through
Hole, Stackable PCB Headers, 87758
Vertical, Through Hole, Stackable PCB
Headers

Material Info

Reference - Drawing Numbers

Application Specification	503940001-AS-000
Packaging Specification	PK-87263-0001-001, PK-87263-300-001
Product Specification	PS-87263-001
Sales Drawing	SD-87263-XX2X-001

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

87263-3225