

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0887328612

Status:


Active

Overview:

USB Products and Solutions

Description:

USB On-The-Go (OTG) Shielded I/O Cable Assembly, USB A-to-Mini B, USB 1.1, 1.0m Length, Black

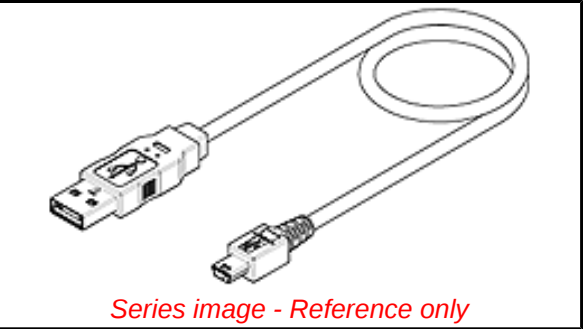

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	88740
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Mini-B
Overview	USB Products and Solutions
Product Name	USB
UPC	756054161425
Physical	
Cable Length	1.0m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	46.700/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm, 2.50mm
Plating min - Mating	0.762µm
Plating min - Termination	4.064µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round
Electrical	
Current - Maximum per Contact	1.0A
Shielded	Yes
Voltage - Maximum	30V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-887328512

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ECHA_01_2020 (16 January 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

88740 Series

Mates With

USB On-The-Go (OTG) Mini-B Receptacle [54819](#) , [48242](#) , [500075](#) , [67503](#). Universal Serial Bus Shielded Receptacle Type A [67329](#) , [67226](#) , [67230](#) , [89485](#). [54366](#) Universal Serial Bus Shielded I/O Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

88732-8612