

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0901471208

Status:


Active

Overview:

C-Grid Connector Products

Description:

C-Grid PC Board Connector, Single Row, Vertical, 8 Circuits, Gold (Au) Plating

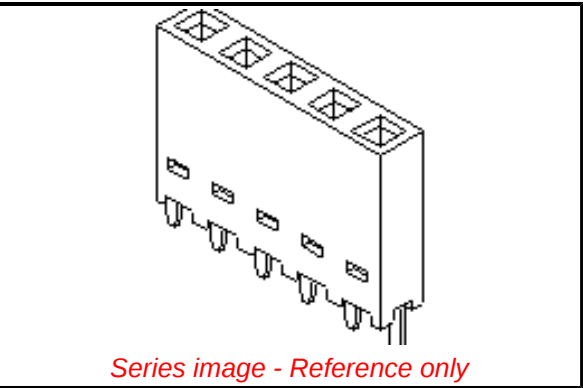

Documents:	
3D Model	Application Specification 713080001-AS-000 (PDF)
Drawing (PDF)	Application Specification 901190001-AS-000 (PDF)
3D Model (PDF)	Packaging Specification PK-90147-001-001 (PDF)
Product Specification PS-99020-0001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	PCB Receptacles
Series	90147
Application	Board-to-Board, Signal
Overview	C-Grid Connector Products
Product Name	C-Grid
UPC	800753538924
Physical	
Circuits (Loaded)	8
Circuits (maximum)	8
Color - Resin	Black
Durability (mating cycles max)	100
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	0.685/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	2.90mm
PCB Locator	No
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Tube
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Plating min - Mating	0.381µm
Plating min - Termination	3.048µm
Polarized to PCB	No
Temperature Range - Operating	-55° to +125°C
Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	3.0A
Grounding to PCB	No
Voltage - Maximum	350V

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Contained Per -	
D(2021)4569-DC (8	
July 2021)	
Dipentyl phthalate	
bis(2-(2-	
methoxyethoxy)ethyl)	
ether	
Benzo(ghi)perylene	
Octanoic acid,	
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-	
pen	
Dodecamethylcyclohexasiloxane	
Decamethylcyclopentasiloxane	
Octamethylcyclotetrasiloxane	
1,2-diethoxyethane	
Dibutyltin-dichloride	
1,3-Propanesultone	
C.I. Direct Black 38	
Ammonium-	
pentadecafluorooctanoate	
2,4-Di-tert-butyl-6-(5-	
chlorobenzotriazol-2-	
yl)p	
Disodium-octaborate	
Dibutylbis(pentane-2,4-	
dionato-O,O')tin	
2-(2H-Benzotriazol-2-	
yl)-4,6-	
ditertpentylphenol	
Terphenyl,	
hydrogenated	
1,2-	
Benzenedicarboxylic	
acid, dihexyl ester,	
bra	
diisohexyl phthalate	
1,2-	
Benzenedicarboxylic	
acid, dipentyl ester, br	

Solder Process Data
Lead-freeProcess Capability

WAVE

Material Info

Reference - Drawing Numbers

Application Specification 713080001-AS-000, 901190001-AS-000
Packaging Specification PK-90147-001-001
Product Specification PS-99020-0001-001
Sales Drawing SDA-90147-001

n-pentyl-
isopentylphthalate
Boric acid
Aluminosilicate
Refractory Ceramic
Fibres
Zirconia
Aluminosilicate
Refractory Ceramic
Fibr
Nonadecafluorodecanoic
acid (PFDA) and its
sodiu
Tris(4-nonylphenyl,
branched and linear)
phosphi
Perfluorobutane
sulfonic acid (PFBS)
and its sal
Fluoranthene
Pyrene
Dioctyltin dilaurate,
stannane, dioctyl-,
bis(co
Perfluorononan-1-
oic acid
(2,2,3,3,4,4,5,5,6,6,7
Methylhexahydrophthalic
anhydride
reaction mass of
2-ethylhexyl 10-
ethyl-4,4-dioct
Perfluorohexane-1-
sulphonic acid and its
salts
Lead chromate
Tris(2-chloroethyl)
phosphate
Boric acid, disodium
salt, hydrate
Strontium-chromate
1,2-
Benzenedicarboxylic
acid, di-C7-11-
branched
bis(2-methoxyethyl)
ether
1,2-
Benzenedicarboxylic
acid, bis(2-
methoxyethyl
1,2-Dimethoxyethane
1,2-bis(2-
methoxyethoxy)ethane
Decabromodiphenylether
Cadmium-oxide
Cadmium-sulphide
Lead
Cadmium
pyrochlore, antimony
lead yellow
Lead-dinitrate
Lead oxide sulfate
(Pb2O(SO4))
Lead-titanium-trioxide

Pentalead-tetraoxide-sulphate
Trilead-dioxide-phosphonate
Tetralead-trioxide-sulphate
Dioxobis(stearato)trilead
Lead titanium zirconium oxide
Cyanamide, lead(2+) salt (1:1)
Cadmium Hydroxide
Sulfurous Acid, Lead Salt, Dibasic
Silicic acid (H2Si2O5), barium salt (1:1), lead-
[Phthalato(2-)]dioxotrilead
Fatty Acids, C16-18, Lead Salts
N,N-Dimethylformamide
Dicyclohexyl-phthalate
Dihexyl-phthalate
Phenanthrene
Imidazolidine-2-thione
Halogen-Free Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[90147](#) Series

Mates With
[90120](#) , [90121](#)

Use With
[90120](#) , [90121](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90147-1208](#)