


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901560162](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Crimp Housing Single Row, 22 Circuits, Black

Documents:
[3D Model](#) [Application Specification 901190001-AS-000 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification PK-90156-0001-001 \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification		
UL		E29179
General		
Product Family		Crimp Housings
Series		90156
Application		Signal, Wire-to-Board
Overview		C-Grid III Interconnects
Product Name		C-Grid III
UPC		800753530133
Physical		
Breakaway		No
Circuits (maximum)		22
Color - Resin		Black
Gender		Receptacle
Glow-Wire Capable		No
Lock to Mating Part		Yes
Material - Resin		PPO
Net Weight		1.656/g
Number of Rows		1
Packaging Type		Bag
Panel Mount		No
Pitch - Mating Interface		2.54mm
Temperature Range - Operating		-55° to +105°C

Material Info		
Reference - Drawing Numbers		
Application Specification		901190001-AS-000
Packaging Specification		PK-90156-0001-001
Product Specification		PS-99020-0001-001
Sales Drawing		SDA-90156-001

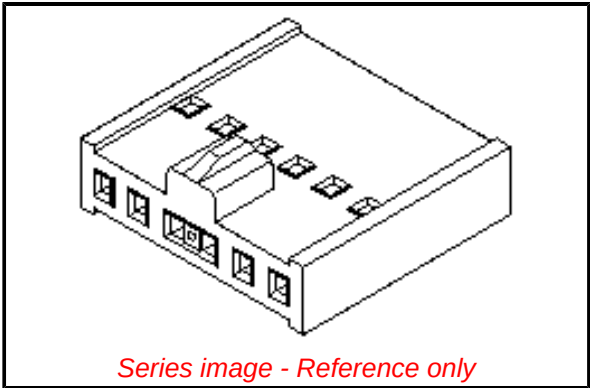

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS Green Image Not Relevant Not Contained

Search Parts in this Series
[90156](#) Series

Mates With
[90120](#) , [90121](#) , [90136](#)

Use With
C-Grid III Crimp Terminal [90119](#)
 C-
Grid III Pre-Crimped Lead [797582022](#) ,
[797582023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90156-0162](#)