

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0923152436
Status: Active
Overview: Picoflex Ribbon-Cable Connectors
Description: Picoflex PF-50 IDT-to-IDT, 24 Circuits, 0.36m Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-99020-0011 \(PDF\)](#)


General
Product Family Cable Assemblies
Series 92315
Application Tooling Part Link 62100-6000
Application Tooling Part Link 62100-6010
Assembly Configuration Dual Ended Connectors
Connector to Connector Picoflex IDT-to-IDT
Overview Picoflex Ribbon-Cable Connectors
Product Name Picoflex
UPC 883906398361

Physical
Cable Length 0.36m
Circuits (Loaded) 24
Color - Resin Natural
Gender Female-Female
Lock to Mating Part None
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester
Net Weight 15.532/g
Packaging Type Bag
Pitch - Mating Interface 1.27mm
Plating min - Mating 2.032µm
Plating min - Termination 2.032µm
Single Ended No
Termination Interface: Style IDT or Pierce
Waterproof / Dustproof No
Wire Insulation Diameter N/A
Wire Size AWG 28
Wire/Cable Type PVC, Ribbon Cable

Electrical
Current - Maximum per Contact 1.2A
Voltage - Maximum 250V

Material Info

Reference - Drawing Numbers
Product Specification PS-99020-0011
Sales Drawing SD-92315-001

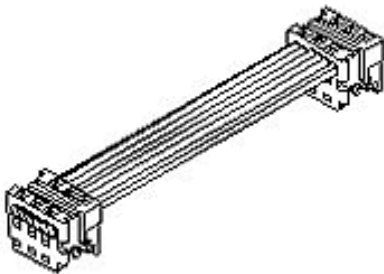

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2018 (15
January 2018)
Halogen-Free
Status
Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[92315](#) Series

Mates With
Picoflex PF-50 Header [90325](#) , [90800](#) ,
[90779](#) , [90715](#) , [90814](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[92315-2436](#)