

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0931753002](#)
Status: **Active**
Overview: [Passive-Safety Pole Connector](#)
Description: Passive-Safety 3 Circuit Female Pole Plug, Black, Overmolded to Armored Orange Cable, Length 2.0m, Sealed to IP68

Documents:

Drawing (PDF)	Test Summary STR-1481-001 (PDF)
Product Specification PS-93175-001-001 (PDF)	Datasheet (PDF)
Product Specification STR-1582-001 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-93175-001-001 (PDF)	

General

Product Family	Cable Assemblies
Series	93175
Assembly Configuration	Single Ended Connector
Connector to Connector	Passive Safety-to-Pigtail
Overmolded	Yes
Overview	Passive-Safety Pole Connector
Product Name	Passive Safety
UPC	884982366145

Physical

Cable Length	2.0m
Circuits (Loaded)	3
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Resin	Polyester Alloy
Net Weight	481.694/g
Packaging Type	Bag
Single Ended	Yes
Waterproof / Dustproof	Yes
Wire Size AWG	16
Wire/Cable Type	Armored


Electrical

Current - Maximum per Contact	3.0A
Shielded	Yes
Voltage - Maximum	250V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-93175-001-001
Product Specification	PS-93175-001-001, STR-1582-001
Sales Drawing	SD-93175-001-001
Test Summary	STR-1481-001

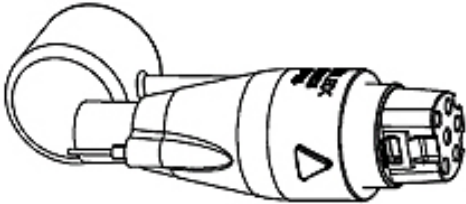

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[93175](#) Series

Mates With

[93175](#) Male Pole Plug

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93175-3002](#)