

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0931753007

Status:


Active

Overview:

Passive-Safety Pole Connector

Description:

Passive-Safety 3 Circuit Female Pole Plug, Black, Overmolded to Armored Orange Cable, Length 20.0m, Sealed to IP68

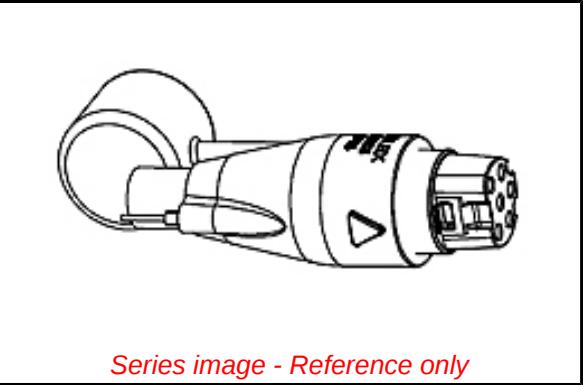

Documents:

[Drawing \(PDF\)](#)

[Product Specification STR-1582-001 \(PDF\)](#)

[Test Summary STR-1481-001 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	93175
Assembly Configuration	Single Ended Connector
Connector to Connector	Passive Safety-to-Pigtail
Overmolded	Yes
Overview	Passive-Safety Pole Connector
Product Name	Passive Safety
UPC	884982705289
Physical	
Cable Length	20.0m
Circuits (Loaded)	3
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Resin	Polyester Alloy
Packaging Type	Bag
Single Ended	Yes
Waterproof / Dustproof	Yes
Wire Size AWG	16
Wire/Cable Type	Armored
Electrical	
Current - Maximum per Contact	3.0A
Shielded	Yes
Voltage - Maximum	250V AC
Material Info	
Engineering Number	93175-3112
Reference - Drawing Numbers	
Product Specification	STR-1582-001
Sales Drawing	SD-93175-001-001
Test Summary	STR-1481-001

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

93175 Series

Mates With

93175 Male Pole Plug

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93175-3007](#)