

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0934635206

Status:


Active

Overview:

Magnetic Jacks

Description:

MXMag Fast Ethernet 4 Core Non-PoE Single-Port RJ45 Connector, 25.40mm Depth, 3.30mm Phy Pin Length, Right-Angle, Inverted Profile, without Shield Tabs, with Green-Yellow LEDs, Industrial Temperature, Tray

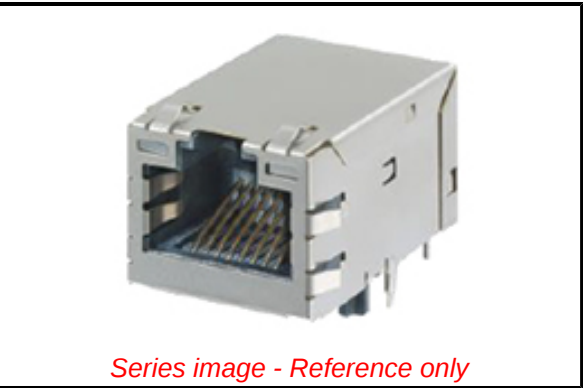

Series image - Reference only

Documents:

- [3D Model](#)[Drawing \(PDF\)](#)[3D Model \(PDF\)](#)[Product Specification 934620001-N \(PDF\)](#)
- [Packaging Specification 934620001-K \(PDF\)](#)[Datasheet \(PDF\)](#)[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Modular Jacks/Plugs
Series	93463
Component Type	PCB Jack
Depth	25.40mm
Magnetic	Yes
Overview	Magnetic Jacks
Performance Category	100Mb
Power over Ethernet (PoE)	Non-PoE
Product Name	Magnetic Jack, MXMag, RJ45
UPC	889056622707

Physical

Color - Resin	Black
Durability (mating cycles max)	2500
Inverted / Top Latch	Yes
Jack Height	14.10mm
Keying to Mating Part	None
Lightpipes/LEDs	LEDs
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold over Palladium Nickel
Material - Plating Termination	Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	7.070/g
Orientation	Right Angle (Side Entry)
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Panel Mount	Yes
Plating min - Mating	0.051µm (Au), 1.016µm (PdNi)
Port Configuration	1x1
Positions / Loaded Contacts	8/8
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole
Wire/Cable Type	N/A

Electrical

Current - Maximum per Contact	0.5A
Grounding to PCB	Yes
Grounding to Panel	Yes
Shielded	Yes
Voltage - Maximum	125V

EU ELV

Not Relevant

EU RoHS

Compliant with
Exemption 7(c)-I

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

93463 Series

Mates With

IEC 60603 / TIA-1096-A

Material Info

Reference - Drawing Numbers

Packaging Specification	934620001-K
Product Specification	934620001-N
Sales Drawing	934630002-000

This document was generated on 09/01/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

93463-5206