

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010069

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect PCB Adapter, Female, 6-Pole, 7.5A, Silver (Ag) Plated Contacts, 3.40mm PC Tail Length, Size «28x4.5»

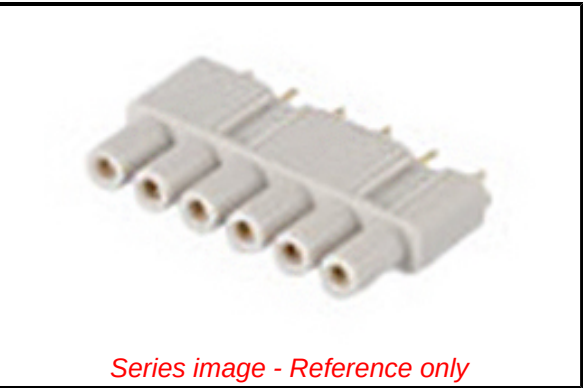

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	«28x4.5»
Component Type	PCB Adapter
Insert Series	S-DD/PCB
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191868271
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Contact	Copper Alloy
Material - Insert	Polyamide
Material - Plating	Silver
Net Weight	2.000/g
Number of Rows	1
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	6
Temperature Range - Operating	-40° to +125°C
Electrical	
Current - Maximum per Contact	7.5A
Voltage - Maximum	250V
Material Info	
Engineering Number	7100.4314.0

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

93601 Series

Use With

S-DD/PCB Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0069](#)