


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0936010092
Status: Active
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Male, 15-Pole, 10A, for Turned or Stamped Crimp Contacts, Size 10A «49x16»

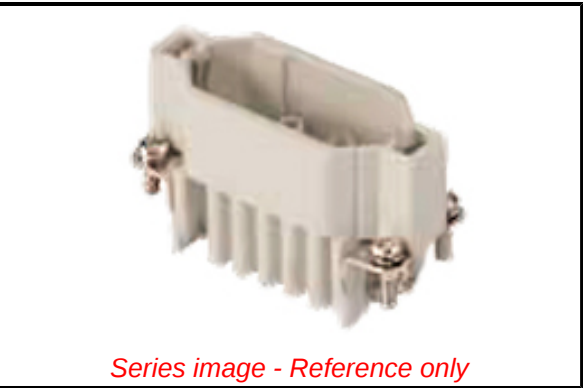

Documents:
RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		10A «49X16»
Component Type		Inserts - Crimp Contact
Insert Series		S-D
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		CSA C22.2 NO. 182.3, EN 175301-801, EN 60664-1, EN 61984, UL 1977
UPC		887191869605
Physical		
Durability (mating cycles max)		500
Flammability		UL 94V-0
Gender		Male
Insert Color		Grey
Material - Insert		Polycarbonate
Net Weight		28.000/g
Number of Rows		3
Packaging Type		Bag
Polarized to Mating Part		Yes
Poles		15
Temperature Range - Operating		-40° to +125°C
Electrical		
Current - Maximum per Contact		10.0A
Voltage - Maximum		250V
Material Info		
Engineering Number		7115.4106.0

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

93601 Series

Mates With

936010091 Male Crimp Contact Insert

Use With

Turned or Stamped Contacts - Male

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0092](#)