


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010095](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Insert for PCB Adapter, Female, 108-Pole, 7.5A, Silver (Ag) Plated Contacts, Size 6B «44x27»

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	6B «44x27»
Component Type	Inserts - PCB Adapters
Insert Series	S-DD/PCB
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191870137
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Contact	Copper Alloy
Material - Insert	Polyamide
Material - Plating	Silver
Net Weight	38.000/g
Number of Rows	6
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	24
Temperature Range - Operating	-40°C to +125°C
Electrical	
Current - Maximum per Contact	7.5A
Voltage - Maximum	250V
Material Info	
Engineering Number	7124.4301.0

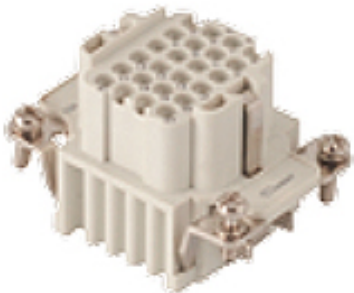

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[93601](#) Series

Mates With
[93601-0097](#) Male Double Contact PCB Adapter Insert

Use With
Size 6B «44x27» Hoods and Housings

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0095](#)