


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0936010112
Status: Active
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Crimp Contact Insert, Male, 64-Pole, 10A, for Turned or Stamped Crimp Contacts, Size 24B «104x27»

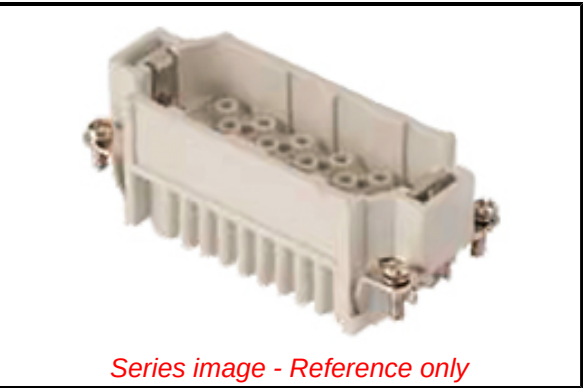

Documents:
RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	24B «104X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-D
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 175301-801, EN 60664-1, EN 61984, UL 1977
UPC	887191870809
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Male
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	71.000/g
Number of Rows	4
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	64
Temperature Range - Operating	-40° to +125°C
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	250V
Material Info	
Engineering Number	7164.4124.0

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

93601 Series

Mates With

936010111 Female Crimp Contact Insert

Use With

Turned or Stamped Contacts - Male

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0112](#)