


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010271](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Crimp Contact Insert, Female, 16-Pole, 16A, Numbered 1-16, for Crimp Contacts, Size 16B «77x27»

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		16B «77X27»
Component Type		Inserts - Crimp Contact
Insert Series		S-EC
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC		887191880198
Physical		
Durability (mating cycles max)		700
Flammability		UL 94V-0
Gender		Female
Insert Color		Grey
Material - Insert		Polycarbonate
Net Weight		61.000/g
Number of Rows		2
Packaging Type		Bag
Polarized to Mating Part		Yes
Poles		16
Temperature Range - Operating		-40° to +125°C
Electrical		
Current - Maximum per Contact		16.0A
Voltage - Maximum		500V
Material Info		
Engineering Number		7316.6063.0

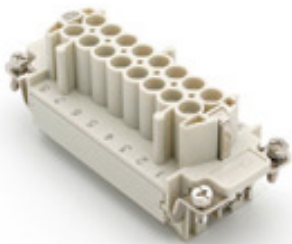

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ED/71/2019 (16 July 2019) Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[93601](#) Series

Mates With
[936010281](#) Male Crimp Contact Insert

Use With
Turned Contacts - Female

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

93601-0271