


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010314](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Screw Terminal Insert, Male, 24-Pole, 16A, Numbered 25-48, without Wire Protection, Silver (Ag) Plated Contacts, Size 24B «104x27»

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	48B «104x62»
Component Type	Inserts - Screw Terminal
Insert Series	S-EST
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191883120
Physical	
Durability (mating cycles max)	700
Flammability	UL 94V-0
Gender	Male
Insert Color	Grey
Lock to Mating Part	Yes
Material - Contact	Copper Alloy
Material - Insert	Polycarbonate
Material - Plating	Silver
Net Weight	112.000/g
Number of Rows	2
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	48
Stripping Length	7.00mm
Temperature Range - Operating	-40° to +125°C
Tightening Test Torque	0.50 Nm
Wire Size AWG	12-20
Wire Size mm²	0.50-4.00
Electrical	
Current - Maximum per Contact	16.0A
Voltage - Maximum	500V
Wire Protection	No
Material Info	
Engineering Number	7324.6108.6

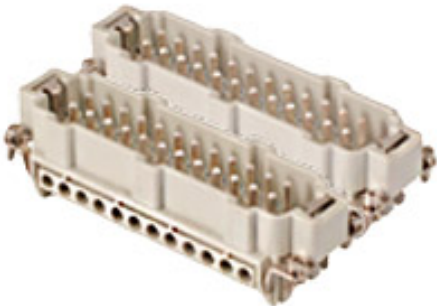

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[93601](#) Series

Mates With
[936010313](#) Female Screw Terminal Insert

Use With
Size 48B «104x62» Hoods and Housings

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0314](#)