


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010317](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: [GWconnect Crimp Contact Insert, Female, 32-Pole, 10A and 16A, Size 10B «57x27»](#)

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	10B «57X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-K8/24
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191883151
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	68.400/g
Number of Rows	6
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	32
Temperature Range - Operating	-40° to +125°C
Electrical	
Current - Maximum per Contact	10.0A, 16.0A
Voltage - Maximum	230V / 400V
Material Info	
Engineering Number	7332.6036.0

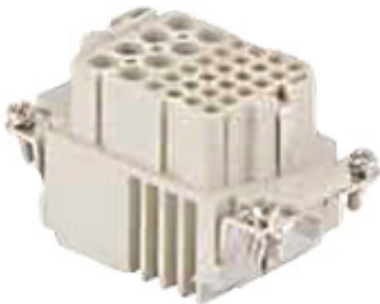

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Not Reviewed	China RoHS
REACH SVHC Not Reviewed	
Halogen-Free Status Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[93601](#) Series

Mates With
[936010320](#) Male Screw Terminal Block Insert

Use With
Size 10B «57x27» Hoods and Housings

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0317](#)