

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010331

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Crimp Contact Terminal Insert, Female, 64-Pole, Size 24B «104x27»

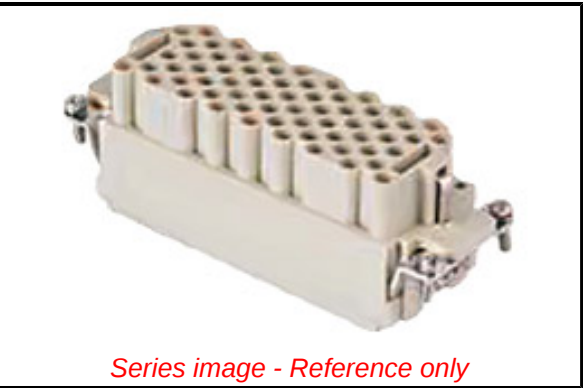

Documents:

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	24B «104X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-EEE
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC	887191883793
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Lock to Mating Part	Yes
Material - Insert	Polycarbonate
Net Weight	84.000/g
Number of Rows	8
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	64
Temperature Range - Operating	-40° to +125°C
Wire Size AWG	12-26
Wire Size mm²	0.14-4.00
Electrical	
Current - Maximum per Contact	16.0A
Voltage - Maximum	500V
Material Info	
Engineering Number	7364.6097.0

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

93601 Series

Mates With

936010332 Male Crimp Terminal Insert

Use With

Size 24B «104x27» Hoods and Housings

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

93601-0331