


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936011860](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect HE - Harsh Environment, Double Lever Hood, Die-cast Aluminum, with 2 Levers, with Gasket, Top Entry, Size 10B «57x27», Extended Pg29 Threaded Fitting, High Construction, Black

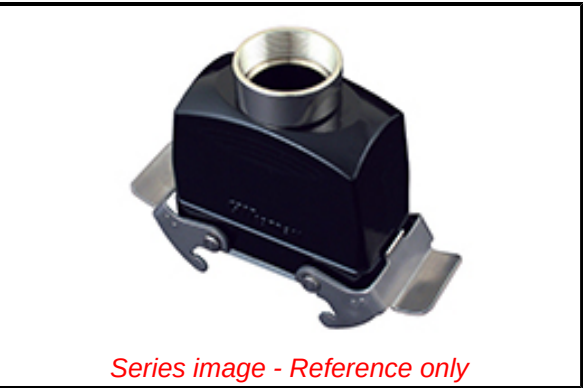

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	10B «57X27»
Component Type	Double Lever Hood
IP Rating	IP66, IP69
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type	HE
UPC	887191854052
Physical	
Entry Location	Top
Hood Coating	Polyester Powder
Hood Color	Black RAL 9005
Lock to Mating Part	Yes
Material - Gasket	NBR
Material - Hood	Die-cast Aluminum
Material - Lever	Galvanized Steel
Net Weight	317.700/g
Number of Levers	2
Packaging Type	Bag
Thread Size	Pg29
Thread Type	(Pg)
Electrical	
Voltage - Maximum	500V
Material Info	
Engineering Number	7810.7105.1

EU ELV
Not Reviewed

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[93601](#) Series

Use With
Size 10B «57x27» S-D, S-DD, S-E, S-EE, S-EP, S-ES, S-HSB, S-ESHV, S-K, S-M, and S-EHV Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-1860](#)