

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936012003

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect STD-HV - Standard-High Voltage, Double Lever Surface Mount Housing, Die-cast Aluminum, with 2 Levers, with Gasket, Size 10B <<57x27>>, Pg21 Thread, High Construction, Grey

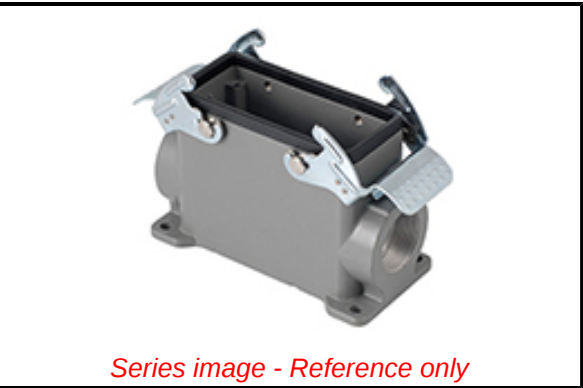

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		10B «57X27»
Component Type		Double Lever SMT Housing
IP Rating		IP66
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type		STD-HV
UPC		887191863887
Physical		
Housing Coating		Polyester Powder
Housing Color		Grey RAL 7037
Lock to Mating Part		Yes
Material - Gasket		NBR
Material - Housing		Die-cast Aluminum
Material - Lever		Galvanized Steel
Mounting Style		Surface Mount
Net Weight		360.930/g
Number of Levers		2
Packaging Type		Bag
Thread Size		Pg21
Thread Type		(Pg)
Electrical		
Voltage - Maximum		830V
Material Info		
Engineering Number		7810.7464.2

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

93601 Series

Use With

Size 10B «57x27» , S-EHV Inserts with Screw Terminals and S-HSB Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-2003](#)