


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936013071](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect HE-HV - Harsh Environment-High Voltage, Double Lever Hood, Die-cast Aluminum, with 2 Levers, with Gasket, Bottom Entry, Size 16B «77x27», M25 Cable Gland, Black

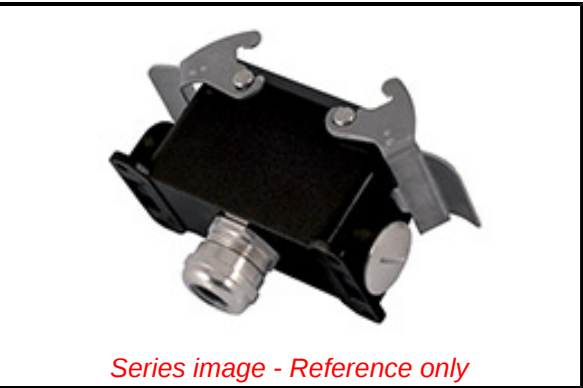

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	16B «77X27»
Component Type	Double Lever SMT Housing
IP Rating	IP66, IP69
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type	HE-HV
UPC	887191868967
Physical	
Entry Location	Bottom
Housing Coating	Polyester Powder
Housing Color	Black RAL 9005
Lock to Mating Part	Yes
Material - Gasket	NBR
Material - Housing	Die-cast Aluminum
Material - Lever	Galvanized Steel
Mounting Style	Surface Mount
Net Weight	379.000/g
Number of Levers	2
Packaging Type	Bag
Thread Size	M25
Thread Type	(M) Metric
Electrical	
Voltage - Maximum	830V
Material Info	
Engineering Number	7816.7565.3

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[93601](#) Series

Use With

Size 16B «77x27» , S-EHV Inserts with Screw Terminals and S-HSB Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-3071](#)