

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936014408

Status:


Active

Overview:

GWconnect® Heavy Duty Connectors (HDC)

Description:

GWconnect HE - Harsh Environment, Double Lever Hood, Die-cast Aluminum, with 2 Levers, with Gasket, Top Entry, Size 32B «77x62», Extended Pg29 Threaded Fitting, High Construction, Black

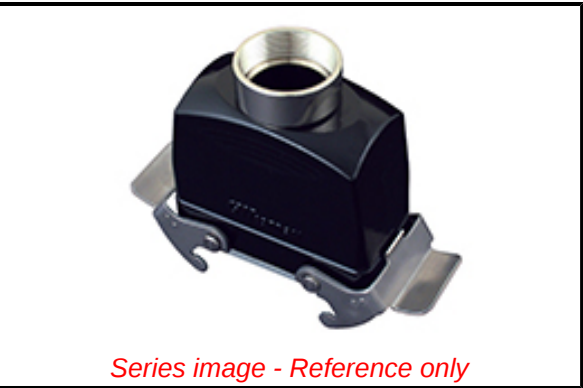

Documents:

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	32B «77X62»
Component Type	Double Lever Hood
IP Rating	IP66, IP69
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type	HE
UPC	887191895048
Physical	
Entry Location	Top
Hood Coating	Polyester Powder
Hood Color	Black RAL 9005
Lock to Mating Part	Yes
Material - Gasket	NBR
Material - Hood	Die-cast Aluminum
Material - Lever	Galvanized Steel
Net Weight	528.700/g
Number of Levers	2
Packaging Type	Bag
Thread Size	Pg29
Thread Type	(Pg)
Electrical	
Voltage - Maximum	500V
Material Info	
Engineering Number	7832.6539.1

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Not Reviewed

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

93601 Series

Use With

Size 32B «77x62» S-D, S-DD, S-E, S-EE, S-EP, S-ES, S-HSB, S-ESHV, S-K, S-M, and S-EHV Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-4408](#)