


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936030058](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Connector Kit, 10 Pole, Series S-E Female-Male Inserts, M20 Metal Cable Gland, M20 Die-cast Aluminum Hood-Side Entry, Bulkhead Mount Housing-Vertical, 2 Lever, Size 10B «57x27», Grey

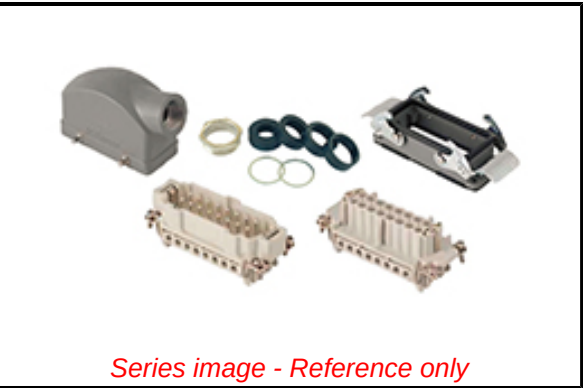

Series image - Reference only

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Kit components
Kit Components [936000046](#) M20 Gland, [936011741](#) M20 Hood, [936010238](#) Male Insert, [936010231](#) Female Insert, [936011575](#) Vertical Bulkhead Housing

General
Product Family Industrial Connectors / Enclosures
Series [93603](#)
Color - Cable Jacket N/A
Component Size 10B «57X27»
Component Type Connector Kit - Female+Male
Insert Series S-E
Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
Product Category Heavy Duty Connectors
Product Name GWconnect
UPC 887191863412

Physical
Lock to Mating Part Yes
Mounting Style Bulkhead
Net Weight 450.000/g
Packaging Type Bag
Thread Size M20
Thread Type (M) Metric

Electrical
Current - Maximum per Contact 16.0A
Voltage - Maximum 500V

Material Info
Engineering Number 7910.7750.5

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[93603](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93603-0058](#)