

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936030077

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Connector Kit, 16 Pole, Series S-E Female-Male Inserts, M25 Die-cast Aluminum Hood-Side Entry, Surface Mount Housing-Vertical, 2 Lever, Size 16B «77x27», Grey

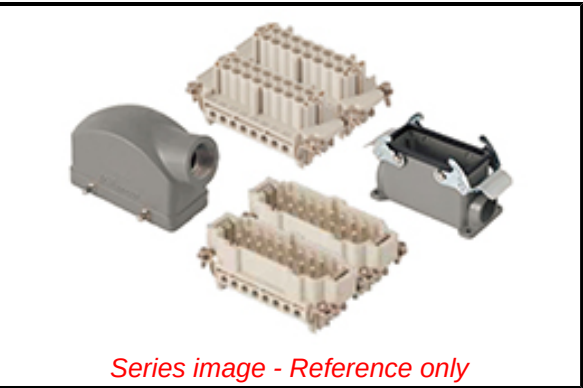

Documents:

RoHS Certificate of Compliance (PDF)

Kit components	
Kit Components	
936012819 M25 Hood, 936010273 Male Insert, 936010263 Female Insert, 936012561 SMT Vertical Housing	
General	
Product Family	Industrial Connectors / Enclosures
Series	93603
Color - Cable Jacket	N/A
Component Size	16B «77X27»
Component Type	Connector Kit - Female+Male
Insert Series	S-E
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
UPC	887191864396
Physical	
Lock to Mating Part	Yes
Mounting Style	Surface Mount
Net Weight	630.000/g
Packaging Type	Bag
Thread Size	M25
Thread Type	(M) Metric
Electrical	
Current - Maximum per Contact	16.0A
Voltage - Maximum	500V
Material Info	
Engineering Number	7916.7761.0

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ED/71/2019 (16 July 2019)	
lead	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

93603 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93603-0077](#)