

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936030100](#)  
**Status:** **Active**  
**Overview:** GWconnect Heavy Duty Connectors (HDC)  
**Description:** GWconnect Connector Kit, 32 Pole, Series S-E Female-Male Inserts, Pg36 Metal Cable Gland, Pg36 Extended Threaded Fitting Die-cast Aluminum Hood-Top Entry, Bulkhead Mount Housing-Vertical, 2 Lever, Size 32B «77x62», Grey

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**Kit components**

Kit Components [93600-0044](#) Pg36 Gland, [93601-4395](#) Pg36 Hood, [93601-0273](#) , [93601-0277](#) Male Inserts, [93601-0263](#) , [93601-0267](#) Female Inserts, [93601-4369](#) Vertical Bulkhead Housing

**General**

Product Family Industrial Connectors / Enclosures  
 Series [93603](#)  
 Component Size 32B «77X62»  
 Component Type Connector Kit - Female+Male  
 Exclude SD Check Yes  
 Insert Series S-E  
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)  
 Product Category Heavy Duty Connectors  
 Product Name GWconnect  
 UPC 887191866260

**Physical**


Lock to Mating Part Yes  
 Mounting Style Bulkhead  
 Packaging Type Bag  
 Thread Size Pg36  
 Thread Type (Pg)

**Electrical**

Current - Maximum per Contact 16.0A  
 Voltage - Maximum 500V

**Material Info**

Engineering Number 7932.6758.5

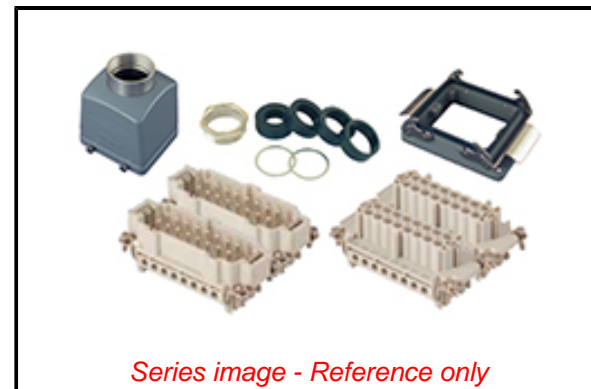

Series image - Reference only

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[93603](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93603-0100](#)