

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936060087

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Patch Cord Cable Assembly, CAT6 Plug-to-Plug, 8P4C Wiring, Fully Shielded, 5.0m

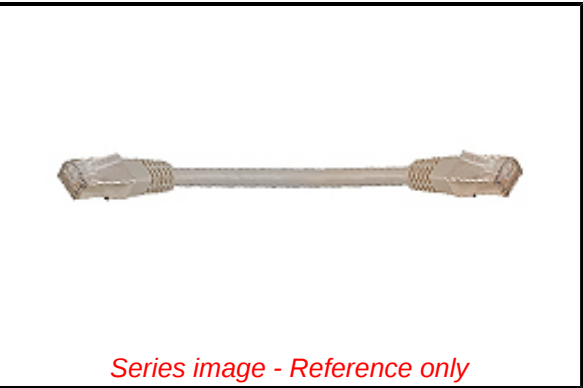

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Connectors / Enclosures
Series	93606
Color - Cable Jacket	Grey
Comments	Class E up to 250 MHz acc. to ISO/IEC 11801, Class E up to 250 MHz acc. to ISO/IEC 11801
Component Type	Cable Assembly
IP Rating	IP20
Length	5.0m
Material - Outer Jacket	LSZH
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Patch Cords
Product Name	GWconnect
Standard	EIA-TIA - 568-C.2, EN 50173-2, IEC 60332.1
Type	RJ45 CAT6
UPC	887191835419
Physical	
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Plating	Gold
Net Weight	200.000/g
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	8p/8C
Temperature Range - Operating	0° to +75°C
Wire Size AWG	26
Material Info	
Engineering Number	2100.3406.5

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

93606 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93606-0087](#)