

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0945504104](#)
Status: **Active**
Overview: [RAST Connector System](#)
Description: 5.00mm Pitch, Rast 5, PA Polyamide (Nylon) 6/6, UL 94V-2, 2 Circuits, Natural, Glow-Wire Capable

Documents:

3D Model	Packaging Specification 945180001-PK-000 (PDF)
Drawing (PDF)	Test Summary TS-94550-001-001 (PDF)
Product Specification PS-94550-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-45499-001-001 (PDF)	

Agency Certification

UL	E29179
----	--------

Application tooling part link


Application Tooling Part Link	216658-0200
Application Tooling Part Link	62201-7500

General

Product Family	Crimp Housings
Series	94550
Application	Power, Wire-to-Board
Comments	This Molex product is manufactured from material that has the following ratings, tested by independent agencies :. a) A Glow Wire Ignition Temperature (GWIT) of at least 775 deg C per IEC 60695-2-13.. b) A Glow Wire Flammability Index (GWFI) above 850 deg C per IEC 60695-2-12.and hence complies with the requirements set out in the International Standard IEC 60335-1 5th edition - household and similar electrical appliances - safety; section 30 Resistance to heat and fire.<P><P>The customers using this product must determine its suitability for use in their particular application through testing or other acceptable means as described in end-product glow-wire flammability test standard IEC 60695-2-11 and any applicable product end-use standard(s).<P>If it is determined during the customer's evaluation of suitability, that higher performance is required, please contact Molex for possible product options. RAST Connector System
Overview	
Product Name	RAST 5
UPC	883906054885

Physical

Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	3.460/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No

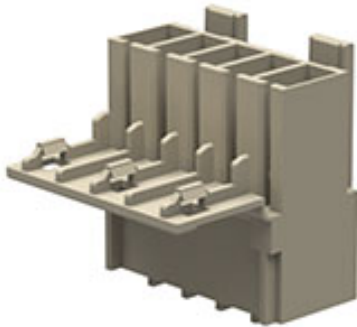

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[94550](#) Series

Mates With

Rast 5 Headers, [90858](#) Vertical Header

Use With

[94518](#) Crimp Terminal

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
RAST 5 Power	2166580200
Semi-Automatic IDC Machine	
Manual Arbor Press, 622017500	
RAST 5	

Pitch - Mating Interface	5.00mm
Pitch - Termination Interface	5.00mm
Polarized to Mating Part	Yes
Ports	1
Stackable	No
Temperature Range - Operating	-40° to +85°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-45499-001-001
Packaging Specification	945180001-PK-000
Product Specification	PS-94550-001-001
Sales Drawing	945180001-000, SD-94550-008-001
Test Summary	TS-94550-001-001

This document was generated on 12/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[94550-4104](#)