

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0945529008](#)
Status: **Active**
Overview: [MOX Products](#)
Description: Housing B USCAR, Receptacle for MOX Terminal 0.64 mm, 8 Circuits

Documents:
[Drawing \(PDF\)](#) [Application Specification AS-94552-001-FR-001 \(PDF\)](#)
[Product Specification 945520002-000 \(PDF\)](#) [Packaging Specification PK-94552-001-001 \(PDF\)](#)
[Application Specification AS-94552-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Housings
Series [94552](#)
Application Power, Wire-to-Board
Overview [MOX Products](#)
Polarization B
Product Name MOX, USCAR
UPC 822348832408

Physical
Circuits (maximum) 8
Color - Resin Black
Gender Receptacle
Glow-Wire Capable No
Material - Resin PBT
Net Weight 3.580/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Temperature Range - Operating -40° to +85°C

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Application Specification AS-94552-001-001, AS-94552-001-FR-001
Packaging Specification PK-94552-001-001
Product Specification 945520002-000
Sales Drawing SD-94552-001-001

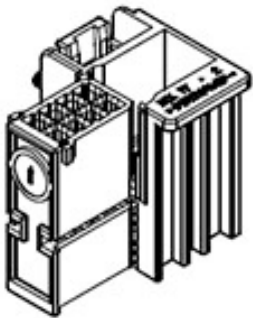

Series image - Reference only

EU ELV
Compliant

EU RoHS Compliant REACH SVHC	China RoHS
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[94552](#) Series

Mates With
2-Bay MOX Header [313412641](#)
3-Bay
MOX Header [313413647](#)

Use With
[98658](#) MOX Crimp Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[94552-9008](#)