

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0950432893

Status:

Active

Overview:

Magnetic and Modular Jacks/Plugs

Description:

Modular Plug, Cat5e, Short Body, Shielded, 8/8, Green Boot

Documents:

3D Model

Drawing (PDF)

Product Specification PS-95043-001 (PDF)

Application Specification AS-95043-001 (PDF)

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

Agency Certification

CSA

LR19980

UL

E107635

General

Product Family

Series

Comments

Modular Jacks/Plugs

95043

Colored Boot|Cable to Plug Tensile Strength: 98.0N,
Colored Boot|Cable to Plug Tensile Strength: 98.0N

Component Type

Magnetic

Overview

Performance Category

Power over Ethernet (PoE)

Product Literature Order No

Product Name

UPC

Wire Plug

No

Magnetic and Modular Jacks/Plugs

5e

N/A

987650-8441

Modular Plug 8/8, RJ45

800754225748

Physical

Boot Color

Color - Resin

Durability (mating cycles max)

Flammability

Inverted / Top Latch

Jack Height

Lightpipes/LEDs

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Orientation

PCB Locator

PCB Retention

Packaging Type

Pitch - Mating Interface

Plating min - Mating

Plating min - Termination

Port Configuration

Positions / Loaded Contacts

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

Waterproof / Dustproof

Wire/Cable Type

Green

Clear

750

94V-2

N/A

N/A

None

Phosphor Bronze

Gold

Tin

Polycarbonate

3.230/g

N/A

No

None

Bag

1.02mm

1.270µm

1.270µm

1x1

8/8

N/A


-40° to +60°C

IDT or Pierce

No

Round

Electrical

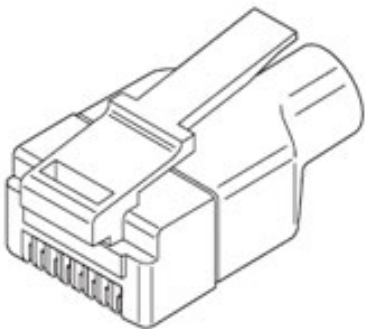

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

95043 Series

Mates With

FCC 68 Jacks

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Parallel Action
Handtool for
Shielded Plug, Cat
5, 8/8 Circuit, Short
Body

690081100

Current - Maximum per Contact	1.5A
Grounding to Panel	N/A
Shielded	Yes
Voltage - Maximum	125V DC

Material Info

Reference - Drawing Numbers

Application Specification	AS-95043-001
Product Specification	PS-95043-001
Sales Drawing	950430001-000

This document was generated on 09/18/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

95043-2893