

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0950432895

Status:

Active

Overview:

Magnetic and Modular Jacks/Plugs

Description:

Modular Plug, Cat5e, Short Body, Shielded, 8/8, Yellow Boot

Documents:

3D Model

Application Specification AS-95043-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-95043-001 (PDF)

Product Literature (PDF)

Agency Certification

CSA

LR19980

UL

E107635

General

Product Family

Modular Jacks/Plugs

Series

95043

Comments

Colored Boot|Cable to Plug Tensile Strength: 98.0N,
Colored Boot|Cable to Plug Tensile Strength: 98.0N

Component Type

Wire Plug

Magnetic

No

Overview

Magnetic and Modular Jacks/Plugs

Performance Category

5e

Power over Ethernet (PoE)

N/A

Product Literature Order No

987650-8441

Product Name

Modular Plug 8/8, RJ45

UPC

800754225823

Physical

Boot Color

Yellow

Color - Resin

Clear

Durability (mating cycles max)

750

Flammability

94V-2

Inverted / Top Latch

N/A

Jack Height

N/A

Lightpipes/LEDs

None

Material - Metal

Phosphor Bronze

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

Polycarbonate

Net Weight

3.080/g

Orientation

N/A

PCB Locator

No

PCB Retention

None

Packaging Type

Bag

Pitch - Mating Interface

1.02mm

Plating min - Mating

1.270µm

Plating min - Termination

1.270µm

Port Configuration

1x1

Positions / Loaded Contacts

8/8

Surface Mount Compatible (SMC)

N/A

Temperature Range - Operating

-40° to +60°C

Termination Interface: Style

IDT or Pierce


Waterproof / Dustproof

No

Wire/Cable Type

Round

Electrical

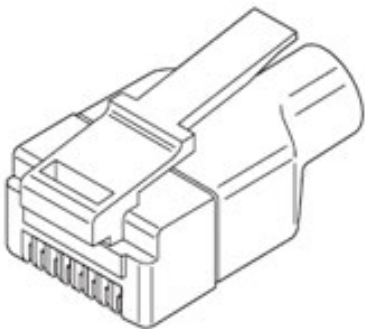

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

95043 Series

Mates With

FCC 68 Jacks

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Parallel Action
Handtool for
Shielded Plug, Cat
5, 8/8 Circuit, Short
Body

690081100

Current - Maximum per Contact	1.5A
Grounding to Panel	N/A
Shielded	Yes
Voltage - Maximum	125V DC
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-95043-001
Product Specification	PS-95043-001
Sales Drawing	950430001-000

This document was generated on 09/21/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

95043-2895