

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982660058

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 102.00mm Cable Length, Tin (Sn) Plating, 6 Circuits

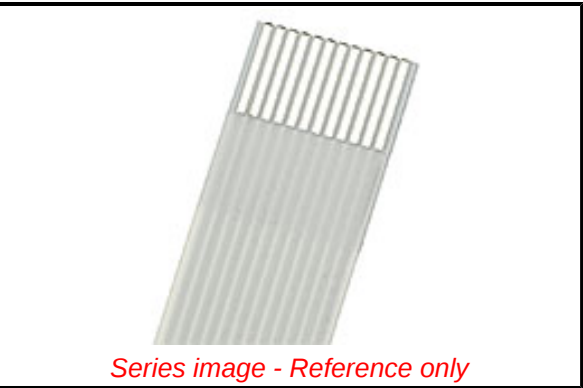

Documents:

Drawing (PDF)

Product Specification PS-98266-001-001 (PDF)

Packaging Specification PK-98266-001-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	98266
Comments	Contacts on opposite sides, Type D
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	756054766927
Physical	
Cable Length	102.00mm
Circuits (Loaded)	6
Contact Layout Type	D (opposite side)
Material - Plating Mating	Tin
Net Weight	0.207/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-98266-001-001
Product Specification	PS-98266-001-001
Sales Drawing	SD-98266-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Compliant

REACH SVHC

Not Contained Per - ECHA_01_2020 (16 January 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

98266 Series

Mates With

Easy-On FFC/FPC Connector:
527450633 , 527460633 , 525590633

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98266-0058](#)