


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0982660219](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 203.00mm Cable Length, Tin (Sn) Plating, 20 Circuits

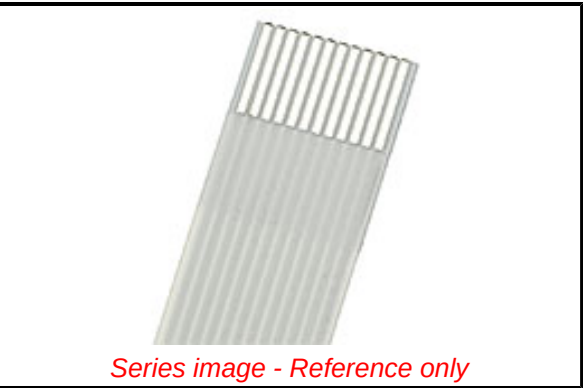

Documents:
[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-98266-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-98266-001-001 \(PDF\)](#)

General	
Product Family	Cable
Series	98266
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	756054771662
Physical	
Cable Length	203.00mm
Circuits (Loaded)	20
Contact Layout Type	A (same side)
Material - Plating Mating	Tin
Net Weight	1.312/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-98266-001-001
Product Specification	PS-98266-001-001
Sales Drawing	SD-98266-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[98266 Series](#)

Mates With

Easy-On FFC/FPC Connector:

[527452033](#) , [527462033](#) , [525592033](#) ,
[525592034](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98266-0219](#)