

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982660277

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 26 Circuits

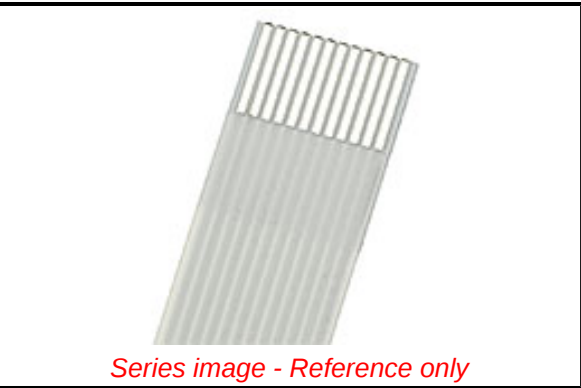

Documents:

Drawing (PDF)

Product Specification PS-98266-001-001 (PDF)

Packaging Specification PK-98266-001-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

|                                    |                                                           |
|------------------------------------|-----------------------------------------------------------|
| <b>General</b>                     |                                                           |
| Product Family                     | Cable                                                     |
| Series                             | 98266                                                     |
| Comments                           | Contacts on the same side, Type A                         |
| Crimp Quality Equipment            | Yes                                                       |
| Overview                           | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name                       | Premo-Flex FFC Jumper                                     |
| UPC                                | 756054772348                                              |
| <b>Physical</b>                    |                                                           |
| Cable Length                       | 102.00mm                                                  |
| Circuits (Loaded)                  | 26                                                        |
| Contact Layout Type                | A (same side)                                             |
| Material - Plating Mating          | Tin                                                       |
| Net Weight                         | 0.876/g                                                   |
| Packaging Type                     | Bag                                                       |
| Pitch - Mating Interface           | 0.50mm                                                    |
| Temperature Range - Operating      | -40° to +105°C                                            |
| Wire Size AWG                      | N/A                                                       |
| Wire/Cable Type                    | Flat Flex Cable                                           |
| <b>Electrical</b>                  |                                                           |
| Current - Maximum per Contact      | 0.5A                                                      |
| Voltage - Maximum                  | 60V AC                                                    |
| <b>Material Info</b>               |                                                           |
| <b>Reference - Drawing Numbers</b> |                                                           |
| Packaging Specification            | PK-98266-001-001                                          |
| Product Specification              | PS-98266-001-001                                          |
| Sales Drawing                      | SD-98266-001                                              |

|                                                               |                   |
|---------------------------------------------------------------|-------------------|
| <b>EU ELV</b>                                                 |                   |
| Not Reviewed                                                  |                   |
| <b>EU RoHS</b>                                                | <b>China RoHS</b> |
| Not Reviewed                                                  |                   |
| <b>REACH SVHC</b>                                             |                   |
| Not Reviewed                                                  |                   |
| <b>Halogen-Free Status</b>                                    |                   |
| Not Reviewed                                                  |                   |
| For more information, please visit <a href="#">Contact US</a> |                   |
| China ROHS                                                    | Not Reviewed      |
| ELV                                                           | Not Reviewed      |
| RoHS Phthalates                                               | Not Reviewed      |

**Search Parts in this Series**  
98266 Series

**Mates With**  
Easy-On FFC/FPC Connector: <br>  
524352633 , 524372633 , 525592633

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98266-0277](#)