

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982661051

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 305.00mm Cable Length, Tin (Sn) Plating, 33 Circuits

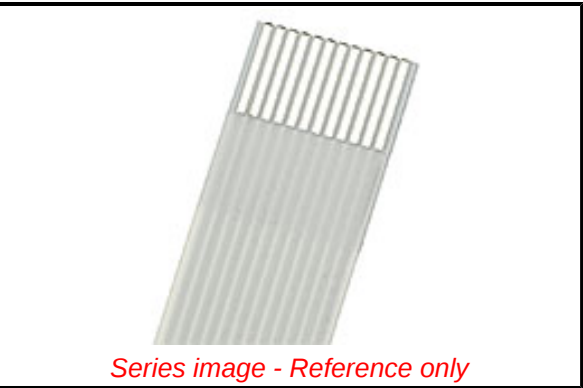

Documents:

Drawing (PDF)

Product Specification PS-98266-001-001 (PDF)

Packaging Specification PK-98266-001-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                                           |
|-------------------------------|-----------------------------------------------------------|
| General                       |                                                           |
| Product Family                | Cable                                                     |
| Series                        | 98266                                                     |
| Comments                      | Contacts on the same side, Type A                         |
| Crimp Quality Equipment       | Yes                                                       |
| Overview                      | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name                  | Premo-Flex FFC Jumper                                     |
| UPC                           | 822350769273                                              |
| Physical                      |                                                           |
| Cable Length                  | 305.00mm                                                  |
| Circuits (Loaded)             | 33                                                        |
| Contact Layout Type           | A (same side)                                             |
| Material - Plating Mating     | Tin                                                       |
| Net Weight                    | 3.311/g                                                   |
| Packaging Type                | Bag                                                       |
| Pitch - Mating Interface      | 0.50mm                                                    |
| Temperature Range - Operating | -40° to +105°C                                            |
| Wire Size AWG                 | N/A                                                       |
| Wire/Cable Type               | Flat Flex Cable                                           |
| Electrical                    |                                                           |
| Current - Maximum per Contact | 0.5A                                                      |
| Voltage - Maximum             | 60V AC                                                    |
| Material Info                 |                                                           |
| Reference - Drawing Numbers   |                                                           |
| Packaging Specification       | PK-98266-001-001                                          |
| Product Specification         | PS-98266-001-001                                          |
| Sales Drawing                 | SD-98266-001                                              |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Relevant                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Reviewed |
| ELV                                                           | Not Relevant |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

98266 Series

Mates With

Easy-On FFC/FPC Connector: <br>  
541043333 , 541323333 , 525593334

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98266-1051](#)